



Locking Fork Terminal T&B Catalog Number:

UPC Number:
Status:
Description:

RC2217M
78621086314
Active

Vinyl Insulated Locking Fork Terminal, Length 1.09 Inches, Width .37 Inches, Maximum Insulation .220, Bolt Hole #8, Wire Range #12-#10 AWG, Color Yellow, Copper, Tin Plated, On Mylar Tape, 500 Pack


WEB_USE

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Locking fork terminals have a specially designed tongue that lets them go on like a fork and stay on like a ring.

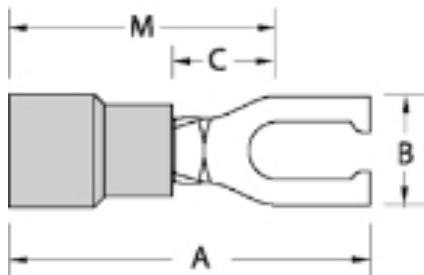

Standards

UL, CSA

General

Insulation Type	Insulated Vinyl
Terminal Series	RC
Material	Copper
Finish	Electro -Tin Plated
Color	Yellow
Wire Range	12-10
Stud Size	#8

Dimension Information

Maximum Insulation (inches)	.220
Stock Thickness	.04
A (inches)	1.09
B (inches)	.37
C (inches)	.27
M (inches)	.90

Specifications

Temperature Rating	105°C
Voltage Rating	600V
Flammability Rating	UL 94 V-0

Tooling

Tool Charts	Available on Website
Application Tools	ERG4001, ERG4003, WT145C, WT2000, WT112M, WT145C
Recommended Tool	12050

Packaging

T&B Order Multiple	500
T&B Inner Pack	500
Package in Units	2500
T&B Sold in UOM	Each
T&B Weight Per UOM	6.88 lbs. per 1000
Alternate Package Qty	10RC-8FL

Application Support

Overview Available on Website

Wire Guide Tables Available on Website

Certifications

RoHS Compliance Yes

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com