

Rigid/IMC Conduit Bodies, Covers & Gaskets

T&B Catalog Number:

UPC Number:

LR250M

Status:

78621096183

Description:

Active



Series 35 Right Side Opening 2-1/2 Inch Conduit Body, Body Material Malleable Iron, Finish Zinc Plating with an Aluminum, Acrylic Coating for Use with Rigid/IMC Conduit

Features

Zinc-plated iron construction with aluminum acrylic coating provides durability, impact resistance and corrosion resistance.

Features tapered, threaded NPT hubs.

Covers available in iron or stamped steel, both zinc-plated and supplied with stainless steel captive screws.

Suitable for use in concrete.

Application

To connect conduit sections

Serve as pulling outlets during conductor installation

Provide easy access for splices in branch conductors

Make 90 degree bends in conduit runs

Act as mounting outlets for wiring devices and lighting fixtures

Provide access to conductors for maintenance and future system changes

General

Trade Size (inches)	2-1/2
Material	Malleable Iron
Finish	Zinc Plating with Aluminum Acrylic Coating
Volume (cu.in.)	142.0
Conduit Body Shape	LR

Dimension Information

Dimension A (inches)	13 5/8
Dimension B (inches)	3 7/8
Dimension C (inches)	5 3/8


Packaging

Package in Units	1
T&B Sold in UOM	Each
T&B Weight Per UOM	10.7 lbs. Each

Application Support

T&B Sales Drawings	wsd-000256
Product Brochure-BlueKote Universal Conduit Elbow	Available on Website
Form 7-Form 8 & Series 35 Conduit Body Available on Website Fill	
Product Brochure-Stainless Steel Form 8 Conduit Outlet Bodies	Available on Website

Certifications

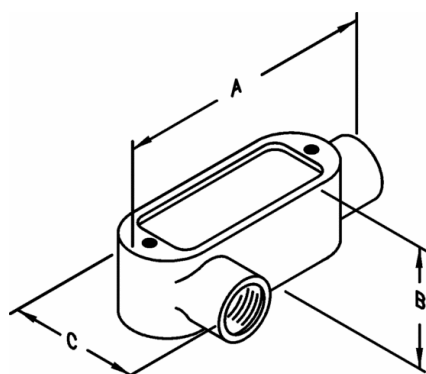

RoHS Compliance

Yes

Certifications



File Nbr:

E 2969

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com