

Pin Terminals

T&B Catalog Number:

UPC Number:

Status:

Description:

RB147PT

78621003421

Active

Nylon Insulated Pin Terminal, Length .87 Inches, Pin Length .390 Inches, Diameter .075 Inches, Wire Range #16-#14 AWG, Color Blue, Copper, Tin Plated, 1,000 Pack

WEB_USE

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Provides an easy and effective way to terminate stranded wire into European/metric-style terminal blocks.

General

Insulation Type	Insulated Nylon
Terminal Series	RB
Material	Copper
Finish	Electro -Tin Plated
Color	Blue
Wire Range	16-14

Dimension Information

Length (inches)	.87
Diameter D (inches)	0.075
Stock Thickness	.03

Specifications

Temperature Rating	105°C
Voltage Rating	300V
Flammability Rating	UL 94 V-2

Tooling

Tool Charts	Available on Website
Application Tools	WT2000, WT1455, ERG4001, ERG4003
Recommended Tool	ERG4001

Packaging


T&B Order Multiple	1000
T&B Inner Pack	1000
Package in Units	10000
Package Type	Bulk
T&B Sold in UOM	Each
T&B Weight Per UOM	0.25 lbs. per 100
Alternate Package Qty	RB14-47PT

Application Support

Overview	Available on Website
Wire Guide Tables	Available on Website

Notes

Most terminals can be put on Mylar Tape for reel fed applications by adding the suffix M to the bulk

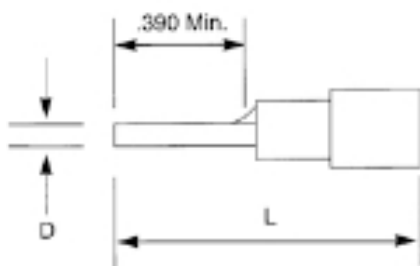

catalog numbers. (I.e. 12050 tool and application dies).

Certifications

RoHS Compliance

Yes

Certifications



File Nbr:

E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com