

## Multiple-Bundle Strip

### T&B Catalog Number:

TC1104

UPC Number:

78621082643

Status:


Active

Description:

Multiple Bundle Mounting Strip, Natural Nylon 6.6 for Temperatures up to 85 Degrees Celsius (185 F), Length of 139.7mm (5.5 Inches), Width of 12.7mm (0.50 Inches), Thickness of 3.17mm (0.125 Inches), Two-Screw Mounting Method, #6 Screw, Military Specified (MIL-SPEC MS3339-4)

### Features

These nylon mounting strips for parallel installation of wire bundles can accommodate up to six closely spaced bundles.

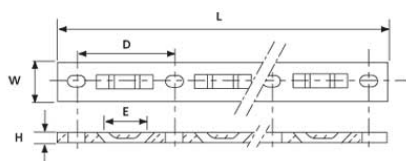

### General

Material	Nylon 6.6
Color	Natural
Mounting Method	Screw
Stud Size	#6 Screw
Max Tie Width Accepted	.19
For Cable Ties	Up to 50 lbs.

### Dimension Information

Length (inches)	5.5
Width (inches)	.500

### Specifications

Military Standard Part No.	MS3339-4
Temperature Rating	-40°F to 185°F
Flammability Rating	UL 94 V-2

### Packaging

T&B Order Multiple	100
T&B Inner Pack	100
Package in Units	500
Package Type	Bulk
T&B Sold in UOM	Each
T&B Weight Per UOM	1.19 lbs. per 100

### Application Support

T&B Sales Drawings	wsd-000328
Material Selection Guide	Available on Website

### Certifications

RoHS Compliance	Yes
-----------------	-----

### Certifications



For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: techsupport@tnb.com