

Multiple-Bundle Strip

T&B Catalog Number:

UPC Number:

Status:

Description:

TC1116


78621082328

Active

Multiple Bundle Mounting Strip, Natural Nylon 6.6 for Temperatures up to 85 Degrees Celsius (185 F), Length of 167.64mm (6.60 Inches), Width of 15.87mm (0.625 Inches), Thickness of 5.15mm (0.203 Inches), Two-Screw Mounting Method, #6 Screw, Military Specified (MIL-SPEC MS3339-9-9)

Features

These nylon mounting strips for parallel installation of wire bundles can accommodate up to six closely spaced bundles.

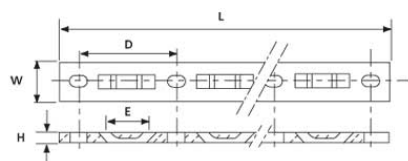

General

Material	Nylon 6.6
Color	Natural
Mounting Method	Screw
Stud Size	#6 Screw
Max Tie Width Accepted	.301
For Cable Ties	Up to 120 lbs.

Dimension Information

Length (inches)	6.6
Width (inches)	.625

Specifications

Military Standard Part No.	MS3339-9
Temperature Rating	-40°F to 185°F
Flammability Rating	UL 94 V-2

Packaging

T&B Order Multiple	100
Package in Units	100
Package Type	Bulk
T&B Sold in UOM	Each
T&B Weight Per UOM	2.56 lbs. per 100

Application Support

T&B Sales Drawings	wsd-000329
Material Selection Guide	Available on Website

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E49405

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.

T&B Technical Support
MS 3B-50

Hours: 7AM - 6PM CDT
Monday-Friday

Memphis, TN 38125
www.tnb.com

8155 T&B Blvd.
Memphis, TN 38125

Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com