



SC-P620

Powered Horn Speaker



Highly Intelligible Speaker with
built-in Digital Power Amplifier

SC-P620 Powered Horn Speaker


The SC-P620 is a highly intelligible and compact horn speaker with a built-in 20W digital power amplifier, that provides public address announcement and remote paging via network video surveillance applications. This powered horn speaker can operate at extreme temperature. It comes with powder-coated finish and stainless steel screws to ensure its weatherproof capability. Ideal choice for both indoor and outdoor application at restricted facilities, train stations, airports and many more.

Key Features

- Integrated 20W power amplifier which utilises latest Class D technology
- Switchable Gain: 8dB, 16dB, 24dB & 32dB
- Internal volume control to allow on-site tuning
- Integration to CCTV systems possible with the majority of IP CCTV systems equipped with an audio line output
- Weatherproof to IP65 rating



Network Camera Configuration

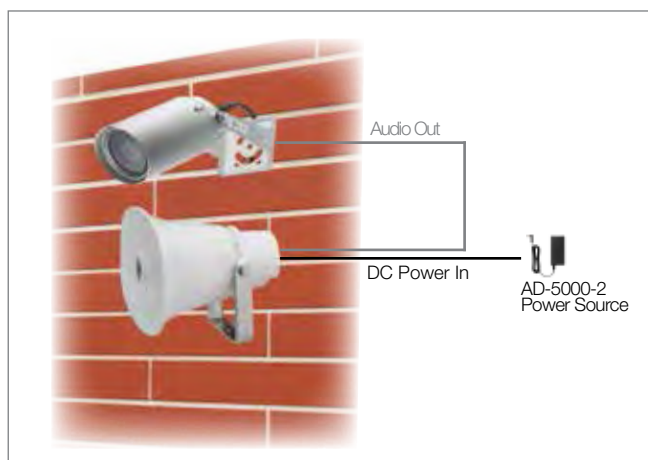

Specification

Power Source	12V DC, 2A (DC Socket "+" Type A: 5.5 x 2.1mm)
Power Consumption	15W (1.25A) at Rated output 25W (2.10A) at Maximum output
Input	0 dB*, 10kΩ, Unbalanced (RCA plug)
Signal Gain	8, 16, 24, 32dB (Factory pre-set to 16dB)
Volume Adjustment	Internal volume control (Factory pre-set to max. position)
Sound Pressure Level	113dB (1W, 1m at 500Hz to 2.5kHz peak level) Max. SPL (above 120dB)
Frequency Response	250 - 10,000 Hz
Operating Temperature	-20C to +55C (must be free from dew condensation)
Dust/Water Protection	IP 65
Finish	Horn Flare: HIPS resin, white (RAL 9010 equivalent) Reflector Horn & Case: ABS resin, white (RAL 9010 equivalent) Bracket, Screws & Bolts: Stainless Steel
Cable Cord	Length: 2m Flying Lead (RCA plug) & DC socket ("+")
Dimensions	292 (W) x 230 (H) x 280 (D) mm
Weight	Approx. 1.8kg
Option	AD-5000-2 (LTE24E-S2-1) AC Adapter



TOA Corporation UK Ltd

www.toa.co.uk

Specifications are subject to change without notice.