



Plain Edge Cable Clamps

T&B Catalog Number:

N6NY-019-9-D

UPC Number:

72849411699

Status:

Active


Description:

Plain Edge Cable Clamp, Natural Nylon 6.6 for Temperatures up to 85 Degrees Celsius (185 F), Width of 12.7mm (0.50 Inches), Thickness of 1.52mm (0.06 Inches), Hole Diameter of 5.16mm (0.203 Inches), #10 Screw Mounting with Closed Diameter of 30.18mm (1.188 Inches), 500 Pack

Features

Fully radiused inside edges with size markings in inches and millimeters for easy identification.

Plain edge cable clamps are designed to perform to NAS-1397P.

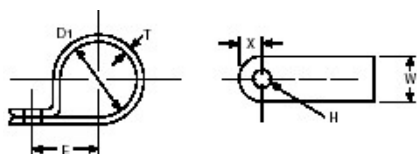

General

Material	Nylon 6/6
Color	Natural
Mounting Method	#10 Screw

Dimension Information

Width (inches)	0.500
Hole Diameter (inches)	0.203
Closed Diameter (inches)	1.187
Max. Wire Bundle Diameter (inches)	1.187
Thickness (inches)	0.060
E (inches)	0.963
X (inches)	0.218

Specifications

Temperature Rating	-40°F to 185°F
--------------------	----------------

Packaging

T&B Order Multiple	500
T&B Inner Pack	500
Package in Units	4000
Package Type	Bulk
T&B Sold in UOM	Each

Application Support

T&B Sales Drawings	wsd-000525
--------------------	------------

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com