



## Insulated Conductor Connectors

**T&B Catalog Number:**

IPC3541

**UPC Number:**

78378633115

**Status:**

Active

**Description:**

Type IPC - Talon Insulation Piercing Connector for Conductor Range  
Main: 350-4/0 AWG, 185-95 MM sq., Tap: 4/0 to #10 AWG, 95-6 MM sq.

### Features

For copper-to-copper, copper-to-aluminum and aluminum-to-aluminum applications (insulated conductor only). Performs as splice or tab for non-tension applications up to 600 volts, depending on size of connector.

Self-insulated for hot line applications. Six sizes cover range from #10 to 500 kcmil.

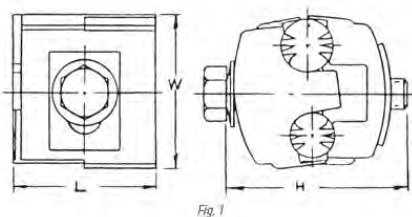


Fig. 1

### General

Style	Type - IPC Talon Insulation Piercing Connectors
Conductor Range (AL or CU) Main	350-4/0 AWG, 185-95 MM sq.
Conductor Range (AL or CU) Tap	4/0-#10 AWG, 95-6 MM sq.
Number of Bolts	1

### Dimension Information

H (inches)	3
L (inches)	2 5/8
W (inches)	2 3/4

### Specifications

Temperature Rating	90°C Max
Voltage Rating	300 Volts Max.

### Packaging

T&B Inner Pack	12
Package in Units	72
T&B Sold in UOM	Each
T&B Weight Per UOM	59 lbs. per 100

### Certifications

RoHS Compliance	Yes
-----------------	-----

### Certifications



File Nbr:

E9809

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: techsupport@tnb.com