



Insulated Conductor Connectors

T&B Catalog Number:

IPC4111

UPC Number:

78378633111

Status:

Active

Description:

Type IPC - Talon Insulation Piercing Connector for Conductor Range Main: 4/0-1/0 AWG, 95-50 MM sq., Tap: 1/0-6 AWG, 50-16 MM sq.

Features

For copper-to-copper, copper-to-aluminum and aluminum-to-aluminum applications (insulated conductor only). Performs as splice or tab for non-tension applications up to 600 volts, depending on size of connector.

Self-insulated for hot line applications. Six sizes cover range from #10 to 500 kcmil.

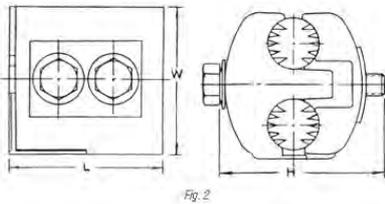


Fig. 2

General

Style	Type - IPC Talon Insulation Piercing Connectors
Conductor Range (AL or CU) Main	4/0-1/0 AWG, 95-50 MM sq.
Conductor Range (AL or CU) Tap	1/0-6 AWG, 50-16 MM sq.
Number of Bolts	2

Dimension Information

H (inches)	3
L (inches)	1 19/32
W (inches)	2 1/2

Specifications

Temperature Rating	90°C Max
Voltage Rating	300 Volts Max.

Packaging

T&B Inner Pack	30
Package in Units	120
T&B Sold in UOM	Each
T&B Weight Per UOM	51.81 lbs. per 100

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com