



BLACKWIRE® 315/325


Top-notch features. Bottom-line value.

Delivering the flexibility to make a better connection.

Value and Flexibility

BLACKWIRE® 315/325

KEY FEATURES

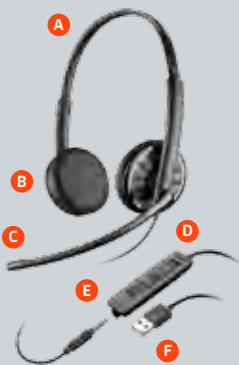

- A Lightweight metal headband
- B Ear cushions fold flat for easy storage
- C Noise-canceling mic with flexible boom
- D PC call answer/end, mute, volume +/-
- E 3.5mm connection
- F USB connection

BLACKWIRE 315 (MONAURAL)



INCLUDED ACCESSORY

- Carrying case for easy storage and portability



MORE HEADSET FOR YOUR UC DOLLAR

The new Plantronics Blackwire 315/325 USB headsets are a simple-to-use, comfortable, and durable option for organizations seeking high-quality, entry-level UC devices. With outstanding audio quality, flexibility with choice of USB or 3.5mm connectivity, and comfortable leatherette ear cushions and lightweight headbands, they deliver top-notch features — and bottom-line value.

SIMPLICITY MEETS DURABLE DESIGN

- Easily manage calls from PC, smartphone or tablet with USB or 3.5mm connectivity
- Ultra-soft leatherette ear cushions fold flat for easy storage and portability in the included carrying case
- Lightweight metal headband offers durability and a customizable, comfortable fit
- Intuitive inline controls to answer/end PC calls, control volume, and mute
- Smartly placed indicator lights and helpful audio alerts give user PC call, mute, and volume status

OUTSTANDING AUDIO QUALITY

- Wideband audio with noise-canceling for high-quality PC telephony
- Dynamic EQ feature automatically adjusts audio for voice or multimedia use
- Noise-canceling microphone filters out background sound
- Enhanced Digital Signal Processing (DSP) provides more natural voice sound
- SoundGuard® technology provides protection against audio spikes

OPTIMIZED FOR UNIFIED COMMUNICATIONS

Connects to	PC or Mac via USB, smartphone and tablet via 3.5mm
Compatible with	Windows® or Mac® OS
Ideal for	Users transitioning to PC telephony for webinars, conference calls, music, and other multimedia applications
PC audio performance	Dynamic EQ, microphone frequency response 100 Hz–10 kHz optimal for PC wideband voice telephony (up to 6,800 Hz), hi-fi stereo (C325) output from 20 Hz–20 kHz, enhanced digital signal processing (DSP), noise-canceling microphone
Hearing protection	SoundGuard: Acoustic limiting for protection against sounds above 118 dBA
Limited warranty	2 years
Models	C315 (monaural), C325 (stereo): UC Standard version built for UC applications and softphones from Avaya®, Cisco®, IBM®, Skype®, and more* C315-M (monaural), C325-M (stereo): Certified for Skype for Business and Optimized for Microsoft® Lync®

*Download the latest release of Plantronics Hub software to get one-touch call answer/end with these softphones.

For more information about the Blackwire 315/325 or other Plantronics products, please visit our website at plantronics.com

GLOBAL CUSTOMER CARE

Backed by Plantronics industry-leading global service and support.

+1-800-544-4660 (US and Canada) +1-831-458-7700 (outside US)