
 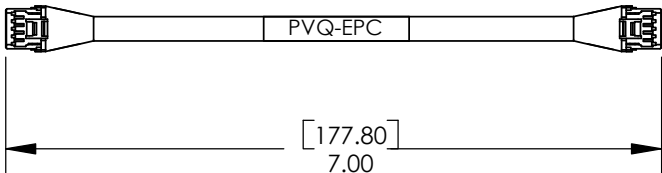
 


PANDUIT P/N	WEIGHT
PVQ-EPC	0.05 LB EA. 23g EA.

- NOTES:
- 1. CONTACT TECHNICAL SUPPORT FOR APPLICATIONS.
 - 2. CONTACT TECHNICAL SUPPORT FOR COMPLETE LIST OF PARTS APPLICABLE FOR USE WITH THIS PART.
 - 3. DIMENSIONS IN BRACKETS ARE IN METRIC.
 - 4. PART INCLUDES:
 - (1) PANVIEW IQ EXPANSION PORT CABLE (PVQ-EPC)



MODEL FILENAME m02676hb_rs485_01.sldprt		SIZE A
DRAWING FILENAME m02676hb_dc109_00a.slddrw		
PanView iQ EXPANSION PORT CABLE, 0.15m CUSTOMER DRAWING		
 PANDUIT ™ CORP. TINLEY PARK, ILL 60477	I.I. NUMBER N/A	
	PRODUCT SPEC/ PKG SPEC N/A	
	ASSEMBLY METHOD/ TEST METHOD N/A	
	SCALE NONE	
 THIRD ANGLE PROJECTION	ALL DIMENSIONS ARE GIVEN IN INCHES, UNLESS OTHERWISE SPECIFIED. DIMENSIONAL TOLERANCES ARE: (.X) ±.03 (.XXX) ±.005 (.XX) ±.01 ANGLES ±1°	
DRAWN BY TCW	REVIEW DRAWING NUMBERS	PART NO. PVQ-EPC
DATE 2/26/08	MATL: SEE NOTES ABOVE	DRAWING NO. 02676-109 Sheet 1 of 1
CHK'D MJD		

R	2/26/08	TCW	MJD	RELEASE TO PRODUCTION	02676-109	MJD	MJD		
REV.	DATE	BY	CHK D	DESCRIPTION	ECN	ECN REV	CUS T	S UP	GM BH