



THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	4 AWG
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	5/8 in.
Stud Size	1/4 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	GRAY
Panduit Die Index No. on Barrel	P29
Alternate Industry Die Index No. () on Barrel	(8)

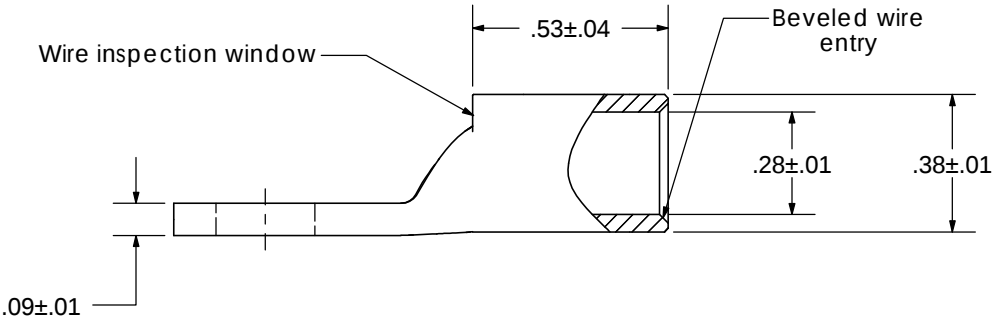

LISTED
Wire Connector

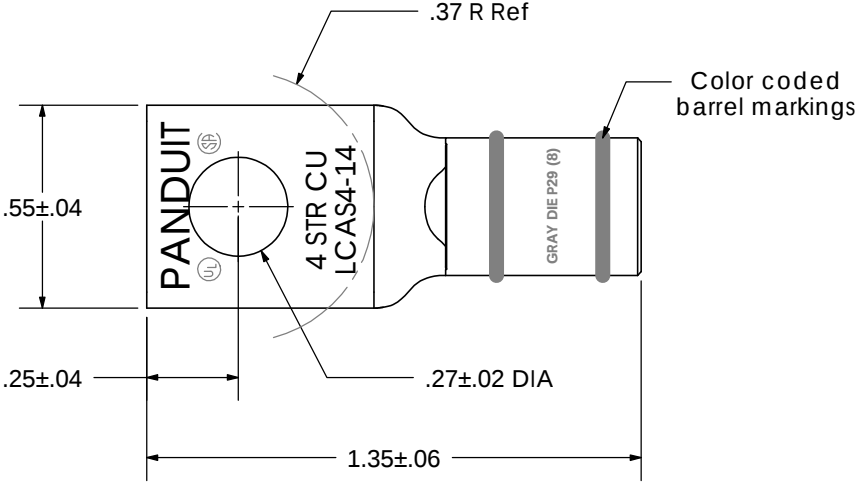

02	8/04	DRL	DRL	REMOVED NAVY NUMBER FROM STAMP	11980
REV	DATE	BY	CHK	DESCRIPTION	ECN

PANDUIT	CORP. TINLEY PARK, ILLINOIS
LCAS4-14-L Copper Lug - One-Hole, Short Barrel	
SCALE N/A	DRAWING NO / CAD FILE LCAS4-14-CUST