



IX-DF



IX-SS

DESCRIPTION:

The IX-DF is an IP addressable stainless steel, flush mount video door station. The IX-SS is an IP addressable stainless steel, flush mount audio only door station. Both units are weather resistant. They connect to the network using CAT-5e/6 cable. The door stations have a built-in dry contact for door release (24V AC/DC, 500mA).

The IX-DF is equipped with a fixed camera, which can be vertically adjusted to 3 positions. The IX-DF is ONVIF Profile S compliant. The door stations can call up to 20 different master stations (IX-MV). An additional 20 master stations can be called using the contact input. The speaker and microphone allow for two-way communication with a master station. The units are 802.3af PoE compliant. Flush mount with the supplied back box or surface mount with the SBX-ISDVF.


IX-DF, IX-SS FEATURES:

- Fixed color video camera (IX-DF only)
- ONVIF Profile S compliant (IX-DF only)
- Weather resistant
- Camera vertical adjustment +15°, 0°, or -8°
- Normally Open dry contact for door release (24V AC/DC, 500mA)
- For indoor or outdoor use
- Stainless Steel
- Connects using CAT-5e/6 cable
- 802.3af PoE compliant

IX-DF, IX-SS

IP Addressable Flush Mount Door Stations for the IX Series

FEATURE CALL-OUT:

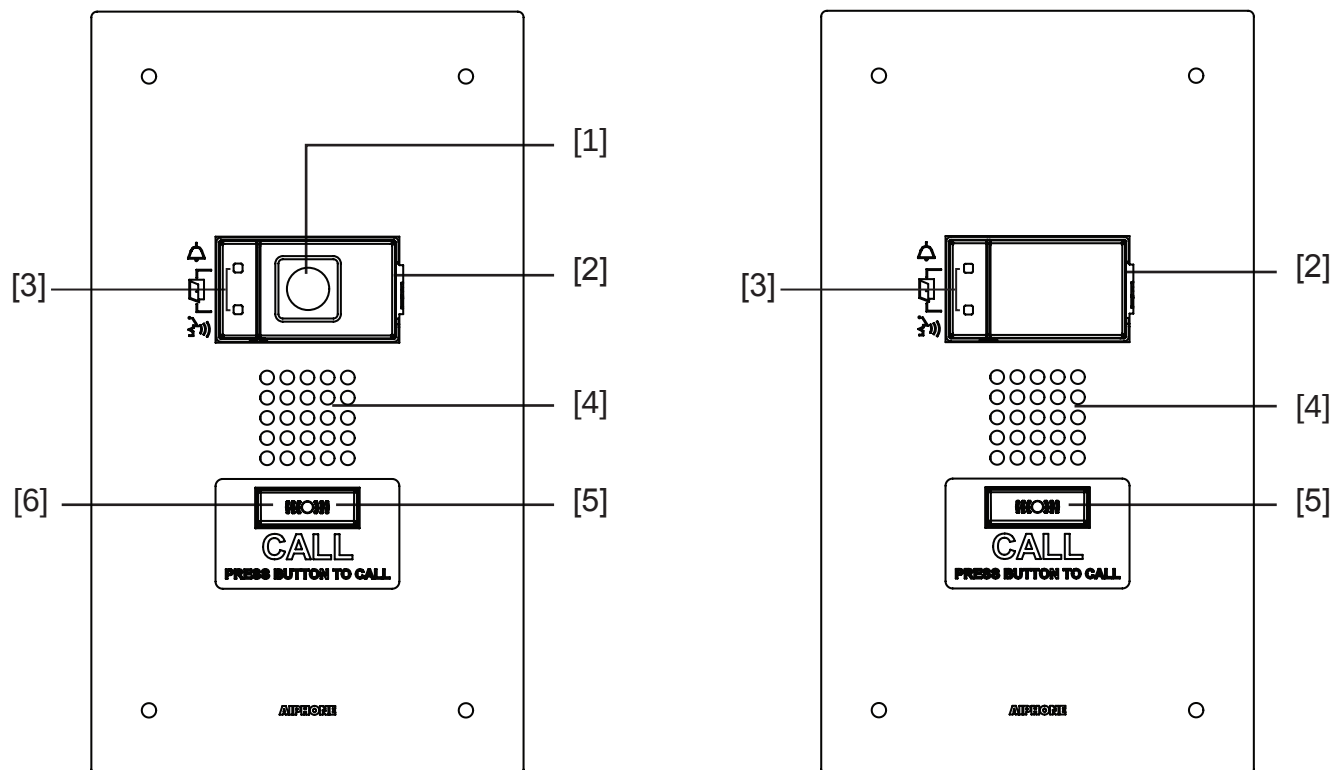

FEATURE CALL-OUT DEFINITIONS:

- [1] Camera
- [2] Microphone
- [3] Status LED's
- [4] Speaker
- [5] Call button
- [6] White LED (for night viewing)

SPECIFICATIONS:

- Power Source: 802.3af PoE compliant
- Communication: Open voice, hands-free
- Camera: 1/4" color CMOS VGA
- Min. illumination: 5 Lux
- Wiring: CAT-5e or CAT-6
- Wiring distance: 330'
- Door release: 24V AC/DC, 500mA (N/O, COM, N/C)
- Operating Temp: -40° - 140°F (-40° - 60°C)
- Ingress Protection: IP55
- Dimensions: 10-7/16"H x 5-7/8"W x 2"D