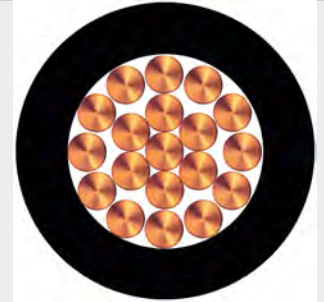


FLRY 25,0/8,5**Application**

Battery

Description

PVC automotive cable, hot-pressure resistant

Technical data

Product number	76781612A
Code	FLRY 25,0/8,5
Cable structure	Round
No. of strands	196
No. of cores	1
Conductor material	Cu-ETP1 W / BL
Insulation	PVC/ PVC
Temperature range	-40°C bis +105°C
Nominal cross-section	25 mm ²