

WIP3VDV5

WISH IP H.265 3MP IR Varifocal Vandal Dome Camera

WIP3VDV5 is a True Day/Night, 3MP H.265 IP, Varifocal Vandal Dome Camera. With an effective IR range of 30m IR in Ideal Conditions. DC12V/ PoE





WIP3VDV5

Key Features

- H.265 Video Compression
- 2.8 - 12mm Varifocal Lens
- 30m IR Distance (In Ideal Conditions)
- Two Way Audio
- Multiple Privacy Masking
- Physical Alarm Output
- Alarm Trigger and Alarm Input
- Dedicated App on Smart Phones & Tablets
- RTSP Streaming with or without Authentication
- 3D DNR
- Digital WDR
- CVBS Local Video
- Mirror & Flip Image
- Supports P2P
- Configuration Backup
- Image Export to Micro SD Card
- Alarm Image Size Dependent on Set Stream Resolution

Dimensions (mm)

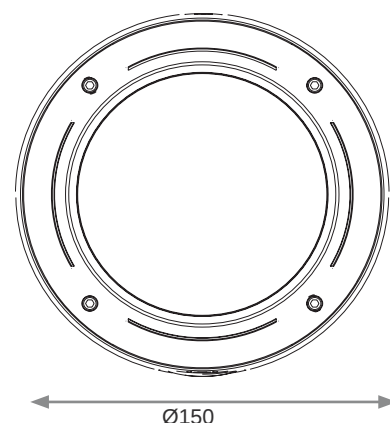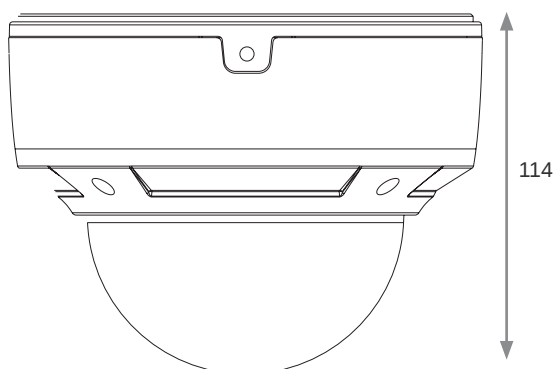

Technical Specification

Model Number	WIP3VDV5
Image Sensor	1/2.7" CMOS
Image Pixels	2048 x 1536
Electronic Shutter	1/25s ~ 1/100,000s
Minimum Illumination	0 Lux (IR LED ON)
Lens	2.8 ~ 12mm
Effective Pixels (H x V)	752 x 582
Digital WDR	Yes
3D DNR	Yes
Video Compression	H.265 / H.264 / MJPEG
Resolution	3MP (2048x1536), 1080P (1920x1080), 720P (1280x720), D1, CIF, 480x240
Multi-Stream	3MP (1~30fps) / 1920 x 1080 (1-30fps) 1280 x 720 (1-10fps) / D1 (1-30fps) / CIF (1-30fps) CIF (1-30fps) / 480 x 240 (1-30fps)
Bit Rate	64Kbps ~ 4Mbps
Encode Mode	VBR / CBR
Quality	Five Levels Under VBR, Freely Adjustable Under CBR
Image Settings	Saturation, Brightness, Contrast, etc Adjustable through Client Software or Web Browser
Audio Compression	G711A
Network Interface	RJ45
Video Output Interface	BNC x1
Audio Interface	Two Way Audio (MIC In x1, MIC Out x1)
RS485	Yes
Alarm Input	1 Ch
Alarm Output	1 Ch
Remote Monitoring	IE Browsing, CMS Remote Control
Online Connection	Support Simultaneous Monitoring for up to 4 Users Support Multi-Stream Real Time Transmission
Protocol	TCP/IP, UDP, DHCP, NTP, RTSP, PPPoE, DDNS, SMTP, FTP
Storage	Support TF Card, Up to 64GB, Network Remote Storage
Smart Alarm	Motion Alarm, Sensor Alarm
Day & Night	ICR
IR Distance	Up to 30m (In Ideal Conditions)
IP Rating	IP66
Power Supply	DC12V / PoE
Operating Conditions	Temperature: -40°C ~ 50°C Humidity: 10% ~ 90%
Dimensions (Ø x L)	Ø150 x 114 mm
Weight	880g

Genie CCTV reserves the right to change specifications without notice. Please contact your representative to confirm current specifications.

Accessories

- FILTERKIT4 - Filter Set Up Kit
- PSU2SM - In-Line DC12V 2A Output, Regulated Switch Mode PSU with Fixing Mount
- POE-INJ01 - PoE Injector, Single Port
- WIPWVDV - Wall Mount Bracket
- WIPCVDV - Ceiling Mount Bracket
- WIPJBVDV - Junction Box for Varifocal Lens Vandal Dome Cameras