

WIP4EBV5 Series

WISH IP 4MP **Autofocus** Network IR Water-Proof Dome Camera

The WIP4EBV5 is a True Day/Night 4MP, IP, IR Dome Camera with a 2.8 -12mm **Autofocus** Lens. With an effective IR Range of up to 30m and autofocus. Available in White and Gun Metal Grey.




WIP4EBV5

WIP4EBV5G

Key Features

- 4MP (2560 x 11440)
- 2.8-12mm **Autofocus** Lens
- H.265/H.264 Compression
- ICR Auto Switch, True Day / Night
- 20 ~ 30m IR night view distance
- 3D DNR
- True WDR
- ROI Coding
- Supports PoE/12VDC Power Supply
- IP66 Drop Ingress Protection
- 2x High Power IR LEDs
- Audio Input (Mic)

Dimensions (mm)

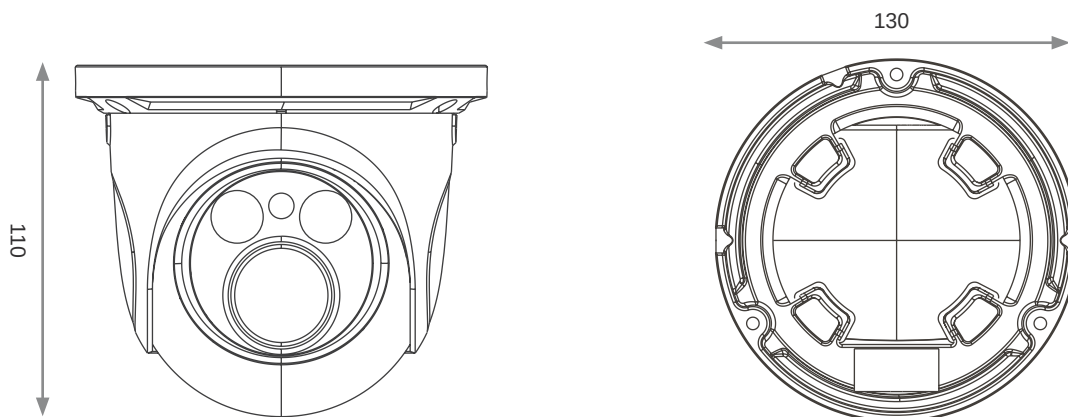

Technical Specification

Model Number	WIP4EBV5	WIP4EBV5G
Image Sensor	1/3 "CMOS	
Image Pixels	2688 x 1520	
Electronic Shutter	1/25s ~ 1/100000s	
Minimum Illumination	0 Lux with 2x IR	
Lens	2.8 ~ 12mm (Autofocus)	
True WDR	Yes	
3D DNR	Yes	
Auto Focus	Yes	
Video Compression	H.265 / H.264 / MJPEG	
Resolution	4MP (2560 x 1440), 3MP (2304x1296), 960P (1280 x 960), 1080P (1920 x 1080), 720P (1280 x 720)	
Bit Rate	64Kbps ~10Mbps	
Encode Mode	VBR/CBR	
Quality	Five Levels under VBR; Freely Adjustable under CBR	
Image Settings	ROI, Saturation, Brightness, Contrast, etc Adjustable through Client Software or Web Browser	
Network Interface	RJ45	
Video Output Interface	BNC 1	
Audio Interface	1x Mic	
Storage Card	Network Remote Storage	
PoE	Yes	
Day and Night	ICR	
Protocol	TCP/IP, UDP, DHCP, NTP, RTSP, PPPoE, DDNS, SMTP, FTP	
Storage	Network Remote Storage	
Smart Alarm	Motion Alarm	
IR Distance	Up to 30m (In Ideal Conditions)	
IP Rating	IP66 (Drop ingress protection)	
Power Supply	POE / 12VDC	
Operating Conditions	Temperature: -20°C ~ 50°C Humidity: 10% ~ 90%	
Dimensions (Ø x L)	Ø130 x 110 mm	
Weight	689g	

Genie CCTV reserves the right to change specifications without notice. Please contact your representative to confirm current specifications.

Accessories

- WIPMPJB - Multi Platform Junction Box