

WIP4VDV5 Series

WISH IP H.265 4MP Varifocal IR Vandal Dome Camera

True Day / Night 4MP IP Vandal Dome Camera, with a 2.8-12mm Varifocal Lens, an IR Distance of up to 30m IR (In Ideal Conditions) and, H.265 Video Compression. DC12V / PoE





WIP4VDV5

Key Features

- 4MP Resolution
- H.265 Video Compression
- MIC / Line in G.711A / U Audio Codec
- RTSP Streaming with or without Authentication
- Multiple Privacy Masking
- Alarm Trigger and Alarm Input with Programmable Schedule
- Supports Own App on Smart Phones & Tablets
- Up to 30m IR Distance (In Ideal Conditions)
- 2.8 – 12mm Varifocal Lens
- Alarm Image Size Dependent on Set Stream Resolution
- 3D DNR
- Digital WDR
- CVBS Local Video
- True Day / Night
- Configuration Backup
- Image Export to Micro SD Card
- P2P Connectivity
- Mirror & Flip Image

Dimensions (mm)

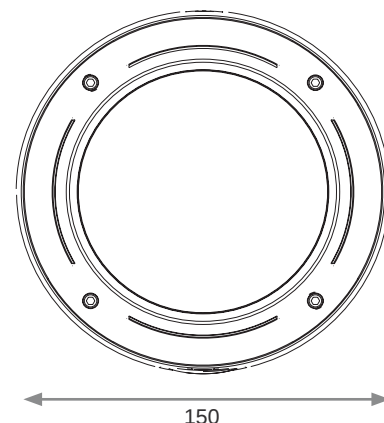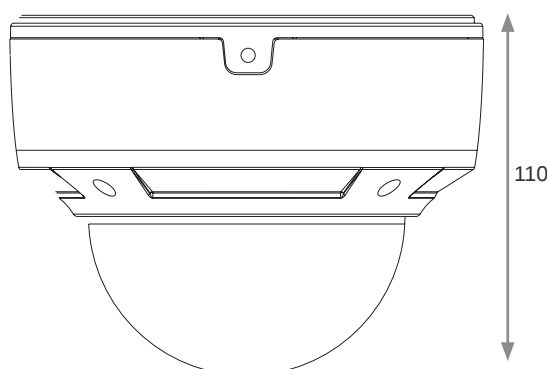

Technical Specification

Model Number	WIP4VDV5	WIP4VDV5G
Image Sensor	1/2.7" CMOS	
Image Pixels	2688 x 1520	
Electronic Shutter	1/25s ~ 1/100,000s	
Minimum Illumination	0.5 Lux (IR LED ON)	
Lens	2.8 - 12mm	
Video Compression	H.265 / H.264 / MJPEG	
Resolution	4MP (2560 x 1440), 1080P (1920 x 1080), 720P (1280 x 720), D1, CIF, 480 x 240	
Multi-Stream	4MP (1-30fps) / 1920 x 1080 (1-30fps) 1280 x 720 (1-10fps) / D1 (1-30fps) / CIF (1-30fps) CIF (1-30fps) / 480 x 240 (1-30fps)	
Bit Rate	64Kbps ~ 10Mbps	
Encode Mode	VBR / CBR	
Quality	Five Levels Under VBR, Freely Adjustable Under CBR	
Image Settings	ROI Coding, Saturation, Brightness, Chroma, Contrast, Wide Dynamic, Sharpen, NR, etc Adjustable through Client Software or Web Browser	
Network Interface	RJ45	
Audio Interface	Two Way Audio (MIC In x1, MIC Out x1)	
Video Output	CVBS Video Output (BNC x1)	
Storage Card	Supports up to 64GB	
RS485	Yes	
Alarm Input	1 Ch	
Alarm Output	1 Ch	
Remote Monitoring	IE Browsing, CMS Remote Control	
Online Connection	Support Simultaneous Monitoring for up to 10 Users Support Multi-Stream Real Time Transmission	
Protocol	TCP/IP, UDP, DHCP, NTP, RTSP, PPPoE, DDNS, SMTP, FTP	
Storage	TF Card Local Storage, Network Remote Storage	
Smart Alarm	Motion Alarm, Sensor Alarm	
Day & Night	ICR	
PoE	Yes	
IR Distance	Up to 30m (In Ideal Conditions)	
IP Rating	IP66	
Power Supply	DC12V / PoE	
Power Consumption	<2.5W	
IR ON	<5W	
Operating Conditions	Temperature: -20°C ~ 50°C Humidity: 10% ~ 90%	
Dimensions (Ø x H)	Ø150 x 110 mm	
Weight	1260g	

Genie CCTV reserves the right to change specifications without notice. Please contact your representative to confirm current specifications.

Accessories

- FILTERKIT4 - Filter Set Up Kit
- PSU2SM - In-Line DC12V 2A Output, Regulated Switch Mode PSU with Fixing Mount
- POE-INJ01 - PoE Injector, Single Port
- WIPWVDV - Wall Mount Bracker
- WIPCVDV - Ceiling Mount Bracket
- WIPJBVDV - Junction Box for Varifocal Lens Vandal Dome Cameras