


LIGHTING

Fluorescent Undercabinet & Heavy Duty Ground Stake UCF SERIES



FLUORESCENT UNDERCABINET

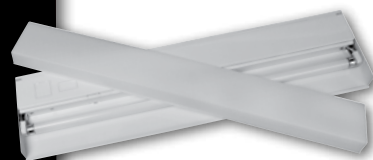

- For fluorescent undercabinet lighting is constructed of heavy duty steel with white powdercoat finish.
- UV inhibited acrylic diffuser with linear prism which snaps in for easy maintenance.
- T-5 4100K lamp included.
- Fluorescent is great for energy savings.
- Ultra thin, 1" thick.
- K.O.s on top, side and back.
- Includes rocker switch.
- Lamp Included.

All dimensional data is listed in inches.

CAT. NO.	DESCRIPTION	VOLTS	LENGTH	WIDTH	DEPTH
UCF128WT5	8 Watt T-5 Electronic Ballast, with Lamp	110-125	12	5	1
UCF2113WT5	13 Watt T-5 Electronic Ballast, with Lamp	110-125	21	5	1
UCF2416WT5	16 Watt T-5 Electronic Ballast, with Lamp	110-125	24	5	1
UCF3321WT5	21 Watt T-5 Electronic Ballast, with Lamp	110-125	33	5	1
UCF4226WT5	26 Watt T-5 Electronic Ballast, with Lamp	110-125	42	5	1

HEAVY DUTY GROUND STAKE

- Adjustable stabilizer and built in wiring compartment.
- Durable molded plastic with die cast fitting for 1/2" NPT threads.
- Two 1/2" coin plugs for enclosed wiring.
- Two 1/2" coin plugs outside for surface and through-wiring.



All dimensional data is listed in inches.

CAT. NO.	DESCRIPTION	HEIGHT	WIDTH	DEPTH
GST	Non-metallic Heavy Duty Ground Stake	19	9	3.5