

Ausrack Wall onyX

19 inch wall mount cabinets



ACCESSORIES

Part Number	Product	Description	ARWX6U450NF	ARWX6U450	ARWX9U450	ARWX12U450NF	ARWX12U450	ARWX12U600	ARWX18U450	ARWX18U600
ARWX2F [▲]	Fan unit	2 fan unit	•	•	•	•	•	•	•	•
ARPRH61010	Power rails – horizontal (10A outlets only) SAA	6 x 10A outlets, 10A plug	•	•	•	•	•	•	•	•
ARPRH61015		6 x 10A outlets, 15A plug	•	•	•	•	•	•	•	•
ARPRH101010		10 x 10A outlets, 10A plug	•	•	•	•	•	•	•	•
ARPRH101015		10 x 10A outlets, 15A plug	•	•	•	•	•	•	•	•
ARDXM12U06	Mesh steel doors	To suit 12RU cabinets				•	•	•		
ARDXM18U06		To suit 18RU cabinets							•	•
ARPCMH1U	Horizontal cable management	1RU	•	•	•	•	•	•	•	•
ARWX450FS [▲]	Fixed shelf - 30kg load, black	285mm	•	•	•	•	•	•	•	•
ARWX450CS	Cantilever shelf - 10kg load, black	450mm	•	•	•	•	•	•	•	•
ARFXKEYR	Spare key	Door, swing frame	•	•	•	•	•	•	•	•
ARC�	Cage nuts	Pack of 50	•	•	•	•	•	•	•	•
ARSTUD100 [▲]	Rack Studs	Pack of 100	•	•	•	•	•	•	•	•
ARSTUD20 [▲]		Pack of 20	•	•	•	•	•	•	•	•

[▲] Available on Request



ARWX2F



ARPRH



ARPCMH1U



ARWX450FS



ARWX450CS



Rack Studs

Ausrack Wall

19 inch wall mount cabinets




ACCESSORIES

Part Number	Product	Description	ARW6U250	ARW6U350	ARW6U450	ARW6U600	ARW12U250	ARW12U350	ARW12U450	ARW12U600	ARW18U350	ARW18U450	ARW18U600	ARW24U350	ARW24U450	ARW24U600
ARW250FS	Fixed shelves - light grey RAL7035 (Requires 4 mounting rails to install)	1RU high x 250mm deep	•	•	•	•	•	•	•	•	•	•	•	•	•	•
ARW350FS		1RU high x 350mm deep			•	•			•	•			•	•		
ARW500FS		1RU high x 500mm deep				•					•			•		
ARW150CS	Cantilever shelves - black	2RU high x 150mm deep	•	•	•	•	•	•	•	•	•	•	•	•	•	•
ARW250CS [▲]		2RU high x 250mm deep		•	•	•		•	•	•		•	•		•	•
ARW350CS		2RU high x 350mm deep			•	•			•	•			•	•		
ARW450CS		2RU high x 450mm deep				•					•			•		
ARPCMH1U	Horizontal cable management	1RU	•	•	•	•	•	•	•	•	•	•	•	•	•	•
ARHCMF1U	Horizontal cable management fingers & cover panels	1RU	•	•	•	•	•	•	•	•	•	•	•	•	•	•
ARHCMF2U		2RU	•	•	•	•	•	•	•	•	•	•	•	•	•	•
ARHCMF4U		4RU	•	•	•	•	•	•	•	•	•	•	•	•	•	•
ARPRH61010	Power rails – horizontal (10A outlets only) SAA	6 x 10A outlets, 10A plug	•	•	•	•	•	•	•	•	•	•	•	•	•	•
ARPRH61015		6 x 10A outlets, 15A plug	•	•	•	•	•	•	•	•	•	•	•	•	•	•
ARPRH101010		10 x 10A outlets, 10A plug	•	•	•	•	•	•	•	•	•	•	•	•	•	•
ARPRH101015		10 x 10A outlets, 15A plug	•	•	•	•	•	•	•	•	•	•	•	•	•	•
ARPAF2	2-way fan kit	Requires 4 mounting rails to install	•	•	•	•	•	•	•	•	•	•	•	•	•	•
ARBP6U	Blanking panel	6RU	•	•	•	•	•	•	•	•	•	•	•	•	•	•
ARWMR6U	Mounting rail pair	6RU	•	•	•	•	•	•	•	•	•	•	•	•	•	•
ARWMR12U		12RU					•	•	•	•						
ARCN	Cage nuts	50 pack	•	•	•	•	•	•	•	•	•	•	•	•	•	•
ARSTUD100 [▲]	Rack Studs	Pack of 100	•	•	•	•	•	•	•	•	•	•	•	•	•	•
ARSTUD20 [▲]		Pack of 20	•	•	•	•	•	•	•	•	•	•	•	•	•	•

[▲] Available on Request

TECHNICAL DRAWINGS

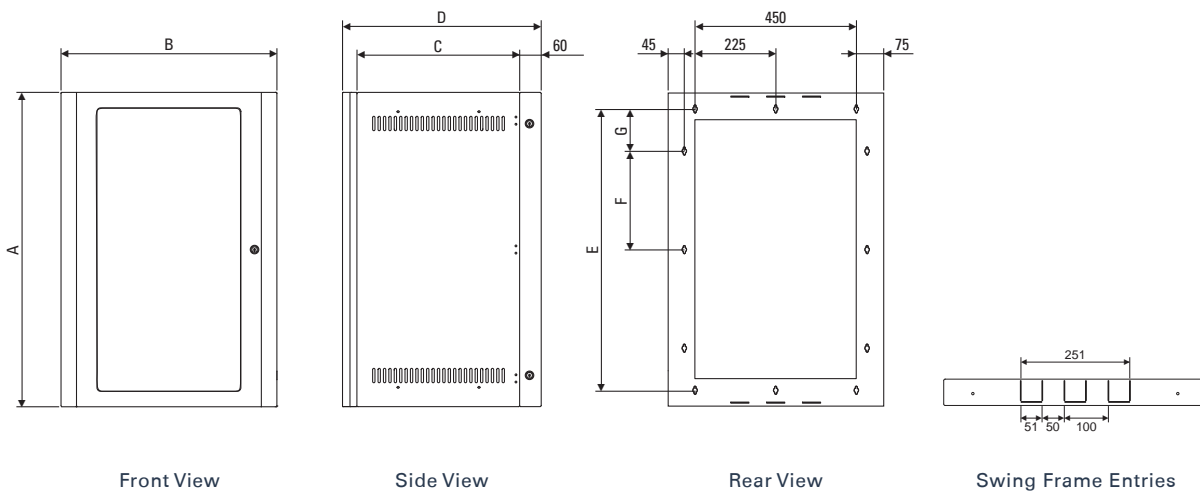

Ausrack Floor onyx

19 inch light duty network cabinets



ACCESSORIES

Part Number	Product	Description	ARFX6622U	ARFX6822U	ARFX6632U	ARFX6832U	ARFX6932U	ARFX6642U	ARFX6842U	ARFX6942U	ARFX6647U	ARFX6847U	ARFX6947U	ARFX8942U	ARFX8947U
ARDXM22U06		22RU x 600mm wide	•	•											
ARDXM32U06		32RU x 600mm wide			•	•	•								
ARDXM42U06	Mesh steel doors (60% open mesh)	42RU x 600mm wide						•	•	•					
ARDXM42U08		42RU x 800mm wide												•	
ARDXM47U06		47RU x 600mm wide									•	•	•		
ARDXM47U08		47RU x 800mm wide													•
ARXD42U06		42RU x 600mm wide						•							
ARXD42U08	Split mesh double doors (60% open mesh)	42RU x 800mm wide							•						
ARXD47U06		47RU x 600mm wide								•					
ARXD47U08		47RU x 800mm wide										•			
ARXFL350		1RU high x 350 deep	•	•			•		•	•					
ARXFL550	Fixed shelves - 30kg load, black	1RU high x 550 deep		•	•			•		•		•			
ARXFL710		1RU high x 710 deep				•			•		•	•	•		
ARWX450CS	Cantilever shelves - 10kg load, black	2RU high x 450 deep	•	•	•	•	•	•	•	•	•	•	•	•	•
ARXKBC350		1RU high x 350 deep	•	•			•		•	•					
ARXKBC550	Keyboard shelves - 10kg load, black	1RU high x 550 deep		•	•			•		•		•			
ARXKBC710		1RU high x 710 deep				•			•		•	•	•		
ARPCMH1U	Horizontal cable management	Rings - 1RU	•	•	•	•	•	•	•	•	•	•	•	•	•
ARHCMF1U	Horizontal cable management fingers & cover panels	1RU	•	•	•	•	•	•	•	•	•	•	•	•	•
ARHCMF2U		2RU	•	•	•	•	•	•	•	•	•	•	•	•	•
ARHCMF4U		4RU	•	•	•	•	•	•	•	•	•	•	•	•	•
ARPRH61010		6 x 10A outlets, 10A plug	•	•	•	•	•	•	•	•	•	•	•	•	•
ARPRH61015	Power rails – horizontal (10A outlets only) SAA	6 x 10A outlets, 15A plug	•	•	•	•	•	•	•	•	•	•	•	•	•
ARPRH101010		10 x 10A outlets, 10A plug	•	•	•	•	•	•	•	•	•	•	•	•	•
ARPRH101015		10 x 10A outlets, 15A plug	•	•	•	•	•	•	•	•	•	•	•	•	•
ARFXKEYF	Spare keys	Front door	•	•	•	•	•	•	•	•	•	•	•	•	•
ARFXKEYR		Rear door	•	•	•	•	•	•	•	•	•	•	•	•	•
ARXSPL	Side panel lock kit	Single lock	•	•	•	•	•	•	•	•	•	•	•	•	•
ARFXBK	Baying kit	Brackets	•	•	•	•	•	•	•	•	•	•	•	•	•
ARCN	Cage nuts	50 pack	•	•	•	•	•	•	•	•	•	•	•	•	•
ARSTUD100 [▲]	Rack Studs	Pack of 100	•	•	•	•	•	•	•	•	•	•	•	•	•
ARSTUD20 [▲]		Pack of 20	•	•	•	•	•	•	•	•	•	•	•	•	•

▲ Available on Request

TECHNICAL DRAWINGS

