

Ausrack Floor Server onyX

19 inch light duty server cabinets



- Suitable for use in large data room applications that require a robust and fully featured server racking solution with free flowing movement.
- Features include a 10-way Australian 3-Pin power rail.
- Load rating tested to AS62208-2006
- Manufactured from:
Frame – 2.0mm zinc coated steel
Panel – 1.2mm zinc coated steel
- Powdercoated textured matte black.

Comes standard with:


- Frame and 2 x removable side panels
- Key lockable front mesh door and split mesh rear doors
- 4 x full height RU marked and notched adjustable mounting rails
- 4 x full height vertical cable management systems with snap cover and internal cable rings (800mm wide cabinets only)
- 3 x fixed shelves
- Roof mounted 4-way fan unit and 10-way Australian 3Pin power rail
- Adjustable feet and braked castor kit
- 20 x cage nuts and screws with insertion / removal tool



ORDERING GUIDE

Part Number	RU	Dimensions (mm)			Total Height	Weight (kg)
		Height (A)	Width (B)	Depth (C)		
ARSX6842U	42	1995	600	800	2065	105.0
ARSX6942U	42	1995	600	960	2065	123.0
ARSX6847U	47	2220	600	800	2290	117.0
ARSX6947U	47	2220	600	960	2290	137.0
ARSX8842U	42	1995	800	800	2065	150.0
ARSX8942U	42	1995	800	960	2065	167.0
ARSX8847U	47	2220	800	800	2290	165.0
ARSX8947U	47	2220	800	960	2290	179.0

TECHNICAL DRAWINGS

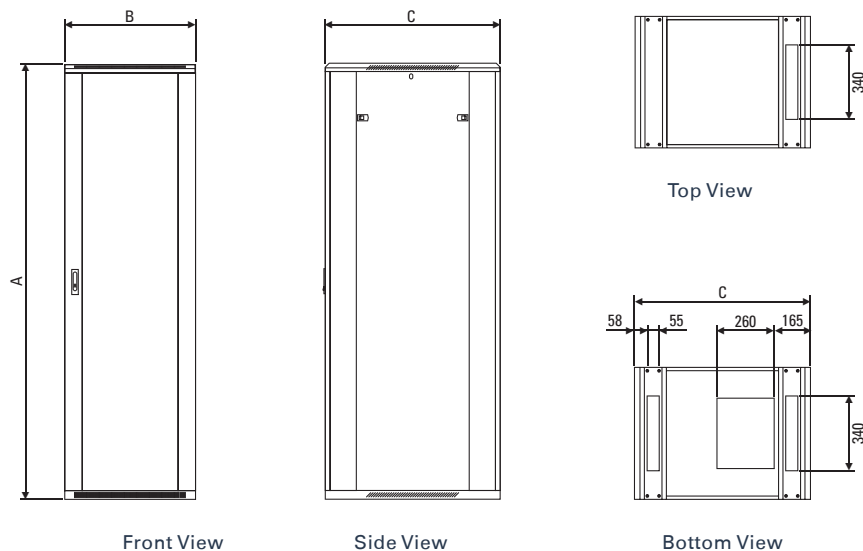

For more information
« brencllosures.com.au/ausrack-floor-server-onyx.htm

Ausrack Floor Server onyX


19 inch light duty server cabinets




ACCESSORIES

Part Number	Product	Description	ARSX6842U	ARSX6942U	ARSX6847U	ARSX6947U	ARSX8842U	ARSX8942U	ARSX8847U	ARSX8947U
ARDXM42U06	Mesh steel door (60% open mesh)	42RU x 600mm wide	•	•						
ARDXM47U06		47RU x 600mm wide			•	•				
ARDXM42U08		42RU x 800mm wide					•	•		
ARDXM47U08		47RU x 800mm wide							•	•
ARDXDD42U06	Mesh steel door – split (60% open mesh)	42RU x 600mm wide	•	•						
ARDXDD47U06		47RU x 600mm wide			•	•				
ARDXDD42U08		42RU x 800mm wide					•	•		
ARDXDD47U08		47RU x 800mm wide							•	•
ARXFL550	Fixed shelves - 30kg load, black	1RU high x 550 deep	•		•		•		•	
ARXFL710		1RU high x 710 deep		•		•		•		•
ARWX450CS	Cantilever shelves - 10kg load, black	2RU high x 450 deep	•	•	•	•	•	•	•	•
ARXKBC550	Keyboard shelves	1RU high x 550 deep	•		•		•		•	
ARXKBC710		1RU high x 710 deep		•		•		•		•
ARPCMH1U	Horizontal cable management	Rings – 1RU	•	•	•	•	•	•	•	•
ARHCMF1U	Horizontal cable management fingers & cover panels	1RU	•	•	•	•	•	•	•	•
ARHCMF2U		2RU	•	•	•	•	•	•	•	•
ARHCMF4U		4RU	•	•	•	•	•	•	•	•
ARPRH61010	Power rails – horizontal (10A outlets only) SAA	6 x 10A outlets, 10A plug	•	•	•	•	•	•	•	•
ARPRH61015		6 x 10A outlets, 15A plug	•	•	•	•	•	•	•	•
ARPRH101010		10 x 10A outlets, 10A plug	•	•	•	•	•	•	•	•
ARPRH101015		10 x 10A outlets, 15A plug	•	•	•	•	•	•	•	•
ARBP6U	Blanking panels (black)	6RU	•	•	•	•	•	•	•	•
ARSXKEY	Spare keys	Door key	•	•	•	•	•	•	•	•
ARXSPL	Side panel lock kit	Single lock	•	•	•	•	•	•	•	•
ARFXBK	Baying kit	Brackets	•	•	•	•	•	•	•	•
ARCN	Cage nuts	50 pack	•	•	•	•	•	•	•	•
ARSTUD100 [▲]	Rack Studs	Pack of 100	•	•	•	•	•	•	•	•
ARSTUD20 [▲]		Pack of 20	•	•	•	•	•	•	•	•


▲ Available on Request

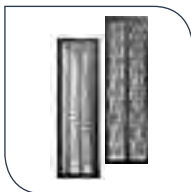

ARDXM & ARDXDD

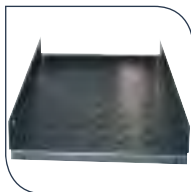

ARXFL

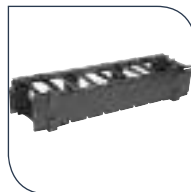

ARHCMF



ARPCMH1U



ARPRH61010