

Ausrack Patch

19" Lab Rack




- Typically used for network patching applications.
- A 2-post frame designed to provide a functional solution where accessibility is a major requirement.
- Open construction suits those who want full access to equipment at all times.
- Designed to bay together using baying kit.
- Supplied flat packed and is easy-to-assemble.
- Base includes fixing points for bolting to floor.
- RU marked rails for easy placement of equipment.
- Manufactured from 1.6mm zinc coated steel.
- Powdercoated textured matte black.

Comes standard with:


- RU marked frame




TECHNICAL DRAWINGS

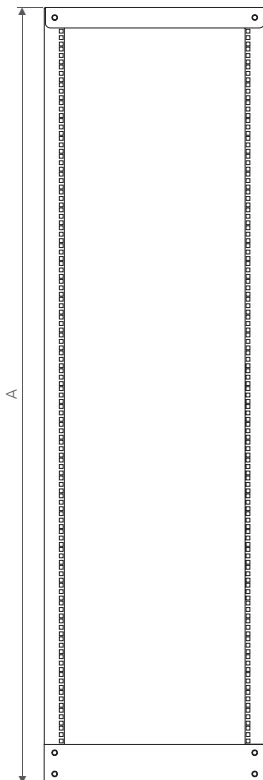

Front View

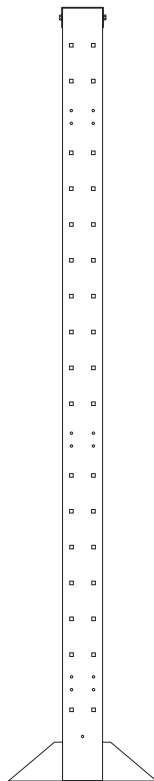

Side View

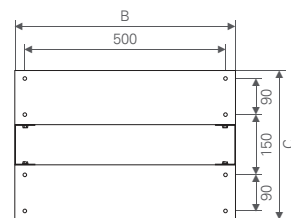

Base View



For more information
« brenclosures.com.au/open_rack.htm

Ausrack Patch

19" Lab Rack



ORDERING GUIDE

Part Number	RU	Dimensions (mm)			Weight (kg)
		Height (A)	Width (B)	Depth (C)	
AL40U	40	1930	550	375	16.5
AL45U	45	2155	550	375	17.0

ACCESSORIES

Product	Part Number	Description	Optional End Cover	AL40U	AL45U
Shelves – cantilever (black)	ARC210	2RU high x 210mm deep	–	•	•
	ARC360	2RU high x 360mm deep	–	•	•
Cable management	AL40UC	Vertical system	ALC40UE	•	
	AL45UC		ALC45UE		•
Cable management rings	ALCMR	1RU	–	•	•
Horizontal cable management rings	ARPCMH1U	1RU	–	•	•
Horizontal Cable Management	ARHCMF1U	Cable fingers and cover panel	–	•	•
	ARHCMF2U		–	•	•
	ARHCMF4U		–	•	•
Vertical Cable Management System	ARVCMS40U10	U-Channel system with cable fingers, connection brackets and cover flaps	–	•	
	ARVCMS40U20		–	•	
	ARVCMS45U10		–		•
	ARVCMS45U20		–		•
Power rails – horizontal (10A outlets only) SAA	ARPRH61010	6 x 10A outlets, 10A plug	–	•	•
	ARPRH61015	6 x 10A outlets, 15A plug	–	•	•
	ARPRH101010	10 x 10A outlets, 10A plug	–	•	•
	ARPRH101015	10 x 10A outlets, 15A plug	–	•	•
Adjustable Joiner Kit	ALJK	Joins two frames together	–	•	•
Cage nuts	ARCN	50 pack	–	•	•
Rack Studs	ARSTUD100 [▲]	Pack of 100	–	•	•
	ARSTUD20 [▲]	Pack of 20	–	•	•

[▲] Available on request



Light duty wall mount 19" bracket. Suitable for applications where cabinet mounting is not practical and space is limited. One side is hinged to allow patch panels and equipment to be swung out for rear access.

Available in 1RU, 2RU and 4RU sizes.

Part Number	RU	To suit cabinets	
		Width (mm)	Depth (mm)
ARWB1U	1	500	200
ARWB2U	2	500	200
ARWB4U	4	500	200