

IDEA™ Panoramic

Wall-Mounted Projection Screen and Markerboard



SPECIFICATION DATA

SUGGESTED SPECIFICATIONS: _____ projection screen(s).
 _____ (H) x _____ (W), _____ (HDTV or Wide) Format center panel. The Interactive Dry Erase Application (IDEA) Panoramic screen surface to consist of a proprietary projection surface permanently bonded to a magnetic substrate that allows use of dry erase markers, interactive stylus and touch interactivity. Projection surface to have a gain of 2½ and a viewing half angle of 25 degrees. Frame will be 1" (25mm) thick with a ¾" (9½mm) bezel in aluminum with a silver finish. Bezel thickness at the screen surface is .06" (1.5mm). Three panel design connected with seam braces. IDEA Panoramic screens include top mounting brackets, lower mounting brackets, 24" length marker tray, a set of four dry erase markers, cleaning cloth and cleaning solution.

HDTV (16:9) Format Dimensions

Viewing Area (H x W)		Center Panel Viewing Area (H x W)		Center Panel Nominal Diagonal		Side Panels Viewing Area (H x W)		Overall Dimensions		Actual Weight		Approximate Shipping Weight	
In.	Cm	In.	Cm	In.	Cm	In.	Cm	In.	Cm	Lbs.	Kg	Lbs.	Kg
46" x 144"	117 x 366	46" x 81¼"	117 x 208	94"	239	46" x 31½"	117 x 79	46¾" x 144¾"	119 x 368	98	44.5	110	49.9
46" x 168"	117 x 427	46" x 81¼"	117 x 208	94"	239	46" x 43¾"	117 x 110	46¾" x 168¾"	119 x 429	113	51.3	128	58.1
46" x 192"	117 x 488	46" x 81¼"	117 x 208	94"	239	46" x 55¾"	117 x 140	46¾" x 192¾"	119 x 490	129	58.5	146	66.2
50" x 144"	127 x 366	50" x 89"	127 x 226	102"	259	50" x 27½"	127 x 70	50¾" x 144¾"	129 x 368	116	52.6	130	59.0
50" x 168"	127 x 427	50" x 89"	127 x 226	102"	259	50" x 39½"	127 x 100	50¾" x 168¾"	129 x 429	131	59.4	147	66.7
50" x 192"	127 x 488	50" x 89"	127 x 226	102"	259	50" x 51½"	127 x 131	50¾" x 192¾"	129 x 490	147	66.7	165	74.8
53" x 144"	135 x 366	53" x 94¼"	135 x 239	108"	274	53" x 24¾"	135 x 63	53¾" x 144¾"	137 x 368	122	55.3	136	61.7
53" x 168"	135 x 427	53" x 94¼"	135 x 239	108"	274	53" x 36¾"	135 x 94	53¾" x 168¾"	137 x 429	139	63.0	156	70.8
53" x 192"	135 x 488	53" x 94¼"	135 x 239	108"	274	53" x 48¾"	135 x 124	53¾" x 192¾"	137 x 490	155	70.3	175	79.4
59½" x 144"	151 x 366	59½" x 106"	151 x 269	121"	307	59½" x 19"	151 x 48	60¼" x 144¾"	153 x 368	136	61.7	151	68.5
59½" x 168"	151 x 427	59½" x 106"	151 x 269	121"	307	59½" x 31"	151 x 79	60¼" x 168¾"	153 x 429	154	69.9	174	78.9
59½" x 192"	151 x 488	59½" x 106"	151 x 269	121"	307	59½" x 43"	151 x 109	60¼" x 192¾"	153 x 490	173	78.5	192	87.1

Wide (16:10) Format Dimensions

Viewing Area (H x W)		Center Panel Viewing Area (H x W)		Center Panel Nominal Diagonal		Side Panels Viewing Area (H x W)		Overall Dimensions		Actual Weight		Approximate Shipping Weight	
In.	Cm	In.	Cm	In.	Cm	In.	Cm	In.	Cm	Lbs.	Kg	Lbs.	Kg
46" x 144"	117 x 366	46" x 73½"	117 x 187	87"	221	46" x 35¼"	117 x 90	46¾" x 144¾"	119 x 368	98	44.5	110	49.9
46" x 168"	117 x 427	46" x 73½"	117 x 187	87"	221	46" x 47¼"	117 x 120	46¾" x 168¾"	119 x 429	113	51.3	128	58.1
46" x 192"	117 x 488	46" x 73½"	117 x 187	87"	221	46" x 59¼"	117 x 150	46¾" x 192¾"	119 x 490	129	58.5	146	66.2
50" x 144"	127 x 366	50" x 80"	127 x 203	94"	239	50" x 32"	127 x 81	50¾" x 144¾"	129 x 368	116	52.6	130	59.0
50" x 168"	127 x 427	50" x 80"	127 x 203	94"	239	50" x 44"	127 x 112	50¾" x 168¾"	129 x 429	131	59.4	147	66.7
50" x 192"	127 x 488	50" x 80"	127 x 203	94"	239	50" x 56"	127 x 142	50¾" x 192¾"	129 x 490	147	66.7	165	74.8
53" x 144"	135 x 366	53" x 84¾"	135 x 215	100"	254	53" x 29¾"	135 x 75	53¾" x 144¾"	137 x 368	122	55.3	136	61.7
53" x 168"	135 x 427	53" x 84¾"	135 x 215	100"	254	53" x 41¾"	135 x 106	53¾" x 168¾"	137 x 429	139	63.0	156	70.8
53" x 192"	135 x 488	53" x 84¾"	135 x 215	100"	254	53" x 53¾"	135 x 136	53¾" x 192¾"	137 x 490	155	70.3	175	79.4
59½" x 144"	151 x 366	59½" x 95¼"	151 x 242	112"	284	59½" x 24¾"	151 x 62	60¼" x 144¾"	153 x 368	136	61.7	151	68.5
59½" x 168"	151 x 427	59½" x 95¼"	151 x 242	112"	284	59½" x 36¾"	151 x 92	60¼" x 168¾"	153 x 429	154	69.9	174	78.9
59½" x 192"	151 x 488	59½" x 95¼"	151 x 242	112"	284	59½" x 48¾"	151 x 123	60¼" x 192¾"	153 x 490	173	78.5	192	87.1

*Add¾" (2 Cm.) to overall frame height for marker tray and right angle brackets.


PRODUCT NOTES

- Custom formats and sizes available upon request. Contact Da-Lite for feasibility.
- Overall frame dimensions +/- 1/4" (0.6 cm).
- Detailed dimensional drawing and installation instructions available upon request.
- Specifications subject to change without notice.
- All Da-Lite surfaces are GREENGUARD GOLD Certified.

WHEN ORDERING, MARK APPROPRIATE SELECTIONS

1. Select size from charts.
2. Select optional accessories:
- ☐ Touch Interactive Bracket Kit - Small
 - ☐ Touch Interactive Bracket Kit - Large
 - ☐ Full length marker tray
 - ☐ ____ carton(s) of Whiteboard Cleaner - 2oz bottles, 12 bottles per carton (one bottle already included with each screen)
 - ☐ ____ pack(s) of cleaning cloths - 12 cloths per pack (one cloth already included with each screen)
 - ☐ ____ set(s) of markers - one each of red, blue, black, and green (one set already included with each screen)

PRODUCT VIEW

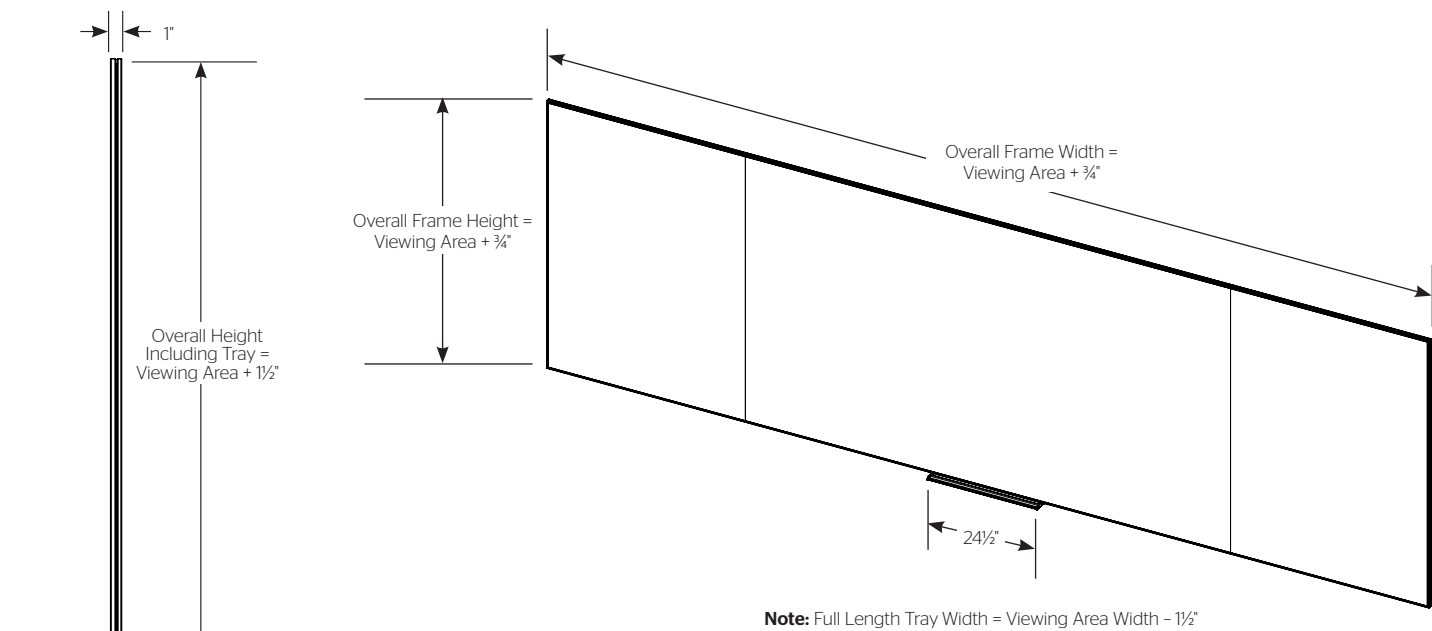

A BRAND OF MILESTONE AV TECHNOLOGIES

www.milestone.com
P 800.622.3737 / 574.267.8101
F 877.325.4832 / 574.267.7804
E info@da-lite.com

In British Columbia, Milestone AV Technologies ULC carries on business as MAVT Milestone AV Technologies ULC.

©2017 Milestone AV Technologies. DL-0487 (Rev 3) 02:17.
Da-Lite is a registered trademarks of Milestone AV Technologies. All other brand names or marks are used for identification purposes and are trademarks of their respective owners. All patents are protected under existing designations. Other patents pending.

Project Name: _____

Architect: _____

Contractor: _____ Phone: _____

Reseller: _____ Phone: _____