


COMPULINK PERFORMANCE PLUS FIBER ASSEMBLY
 2 FIBER 2MM ZIPCORD
 DUPLEX LC TO DUPLEX LC, OM3 OR OM4, RISER OR PLENUM

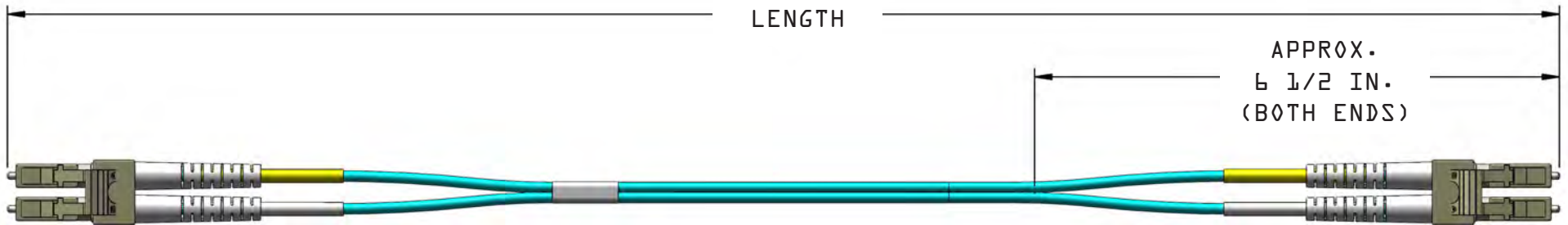

SPECIFICATIONS

	Multimode 850nm		Low Loss Multimode 850nm			
	Insertion Loss	Return Loss	Insertion Loss	Return Loss	Return Loss	
Connector	Typical	Maximum	Minimum	Typical	Maximum	Minimum
LC	0.10 dB	0.50 dB	20 dB	0.10 dB	0.15 dB	20 dB

Optical Fiber Performance

	Wavelength (nm)	Maximum Attenuation (dB/km)	Minimum Overfilled Modal Bandwidth (MHz*km)	Minimum Effective Modal Bandwidth (MHz*km)
OM3	850	3.5	1500	2000
	1300	1.5	200	N/A
OM4	850	3.5	3500	4700
	1300	1.5	500	N/A

TOLERANCE

Cable Overall Length	*Overall Length Tolerance
0 - 5.99 inches	+ 0.125 inches / - 0.125 inches
6 - 11.99 inches	+ 0.25 inches / - 0.25 inches
1 - 2.99 feet	+ 2.0 inches / - 1 inches
3 - 14.99 feet	+ 6 inches / - 3 inches
15 - 24.99 feet	+ 12 inches / - 3 inches
25 - 99.99 feet	+ 1 feet / - 9 inches
100 - 199.99 feet	+ 1 feet / - 2 feet
200 - 299.99 feet	+ 2 feet / - 3 feet
300 - UP feet	+ 3 feet / - 5 feet

*Order length to be Overall Length measured from end face of Connectors.

2 fiber zipcord standard is 2mm, offered in ONFR - Riser Rated or ONFP - Plenum Rated.

