





## Model 34-BMANT24

### 2.4 GHz Single Band WiFi Antenna: NEMA4 Enclosures

Category: WiFi and DAS Antennas




This antenna provided pattern coverage for indoor applications operating in 750-2700 MHz. This economical shot glass style model provided industry leading wideband performance and omni-directional gain. Aesthetic indoor/outdoor antenna for ceiling or vehicle body mounting w/ UV resistant ABS plastic cover.

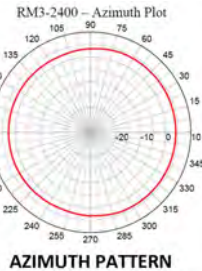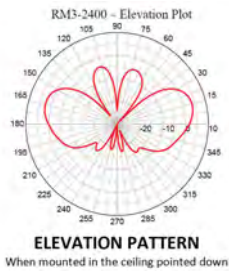

## Features & Benefits

Antenna Pattern:	Omnidirectional
Frequency Range:	750-2700 MHz
Gain without ground plane:	2.5 dBi
Gain with ground plane:	5 dBi
VSWR:	2:1
Connector:	RPTNC
Cable:	12"
Size:	3" Tall, 1.75" Dia.

## Documentation Links

 [Spec Sheet](http://oberoninc.com/index.php?option=com_content&view=article&id=1330&Itemid=399) - oberoninc.com/index.php?option=com\_content&view=article&id=1330&Itemid=399

 [SECTION 27\\_21\\_33 DATA COMMUNICATIONS WIRELESS ACCESS POINTS](http://oberoninc.com/images/WebDocs/SECTION%2027_21_33%20DATA%20COMMUNICATIONS%20WIRELESS%20ACCESS%20POINTS.pdf) -

[http://oberoninc.com/images/WebDocs/SECTION 27\\_21\\_33 DATA COMMUNICATIONS WIRELESS ACCESS POINTS.pdf](http://oberoninc.com/images/WebDocs/SECTION%2027_21_33%20DATA%20COMMUNICATIONS%20WIRELESS%20ACCESS%20POINTS.pdf)

 [Model Viewer](http://oberoninc.com) available at oberoninc.com

*Images and documents may depict similar models in the product series.*