


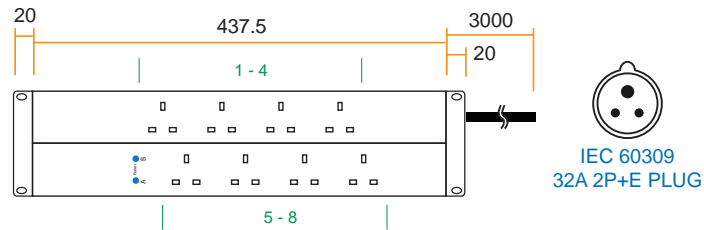

UNIT : mm


Model : H8UK-32A\_EN/3B-1  
AHEU : AHH085000000303111





Cordset : 3 meter 4mm sq H05V V-F cable with IEC60309 32A 2P + E plug  
Input Rating : 32A / 250Vac  
Regulatory :  


For 32A Rating PDU, the models which have 8 socket outlets,  
< CIRCUIT A > Socket #1-4 UK socket outlets can only output 16A maximum.  
< CIRCUIT B > Socket #5-8 UK socket outlets can only output 16A maximum.

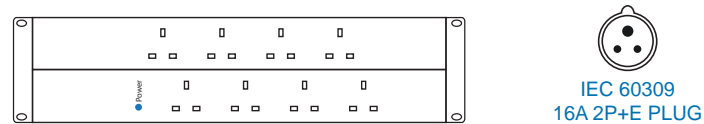

Model : H8UK-16A\_EN/3B-1  
AHEU : AHH085000000203111



Cordset : 3 meter 1.5mm sq H05V V-F cable with IEC60309 16A 2P + E plug  
Input Rating : 16A / 250Vac  
Regulatory :  

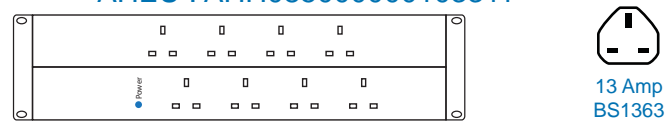Model : H8UK-13A\_BS/3B-1  
AHEU : AHH085000000103311



Cordset : 3 meter 1.5mm sq H05V V-F cable with 13 Amp BS1363 plug  
Input Rating : 13A / 250Vac  
Regulatory :  

Common Specification :

Description : 8 outlets UK, 90 degree  
Receptacles : 8 outlets UK BS1363 13A Rated

PDU Dimension : 110 (H) x 65 (D) x 437.5 (W) mm  
Packing :

Net Weight :  
Gross Weight :



WARNING : The individual user should take care to determine prior to use whether this device is suitable, adequate or safe for the use intended. Since individual applications are subject to great variation, the manufacturer makes no representation or warranty as to the suitability or fitness of these devices for any specific application.

The company reserves the right to modify product specifications without prior notice and assumes no responsibility for any error which may appear in this publication.

Copyright 2013 Austin Hughes Electronics Ltd. All rights reserved.