


CFG

CABLOFIL G-TRAY AND G-MINI

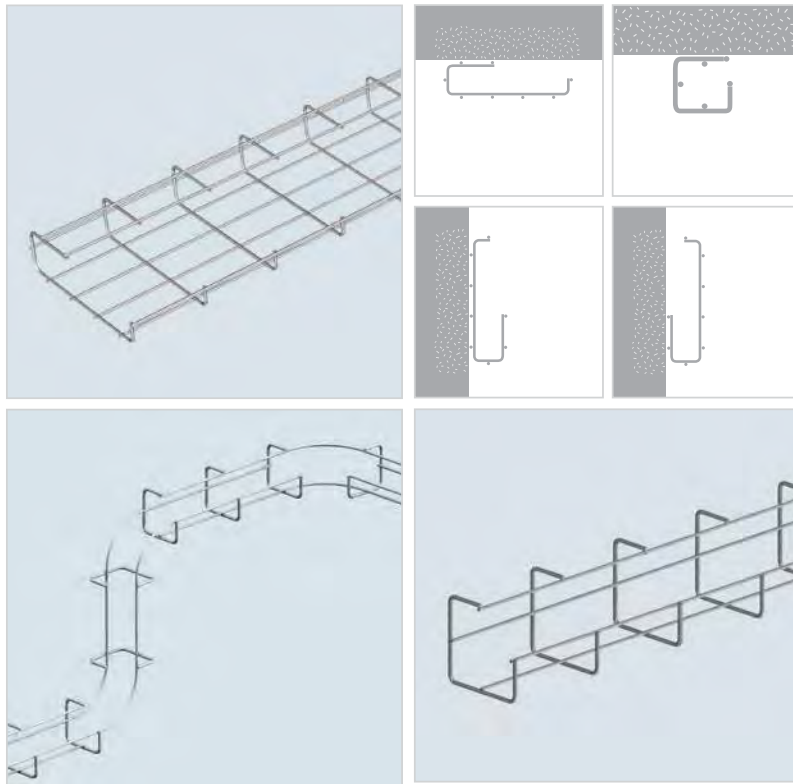


- Unique curved top allows for direct attachment to machinery, ceilings or walls.
- Use CE40 for CFG support attachment.
- 3" overhang on G-Tray allows for direct-mounting in many configurations.
- Unique crosswire design easily bends and lies flat when mounting.
- Use CE25 for G-Mini support attachment.
- G-Mini is a simple and secure routing for small cable runs.
- Use SWK for splicing.

		HEIGHT		WIDTH		LENGTH		WEIGHT		EZ	GC	304L	316L	BL	PE
		INCHES	MM	INCHES	MM	FEET	M	LBS	KG	Ⓢ	Ⓢ			Ⓢ	Ⓢ
CFG 50/100	50	2.0	50	4.0	100	10.0	3	7.0	3.2	003 221	003 223	*	*	941 143	933 935
CFG 50/150	50	2.0	50	6.0	150	10.0	3	10.3	4.7	003 231	003 233	*	*	943 114	*
CFG 50/200	50	2.0	50	8.0	200	10.0	3	10.3	4.7	003 241	003 243	*	*	941 144	933 937
G-MINI	50	2.0	50	2.0	50	10.0	3	8.8	4.0	430 111	944 390	*	430 114	*	*

*Product number was not available at time of print.

CFG APPLICATIONS

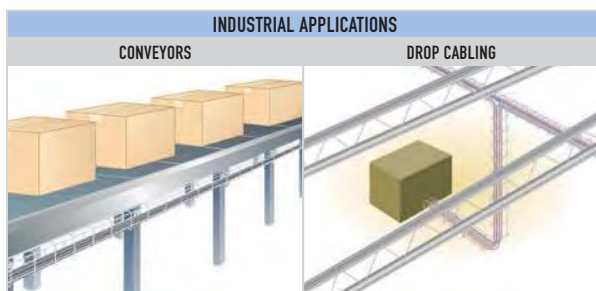

SECURITY APPLICATIONS




G-MINI APPLICATIONS


SECURITY APPLICATIONS



DATA APPLICATIONS

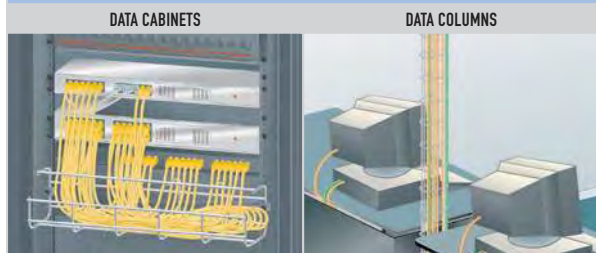

RESIDENTIAL APPLICATIONS

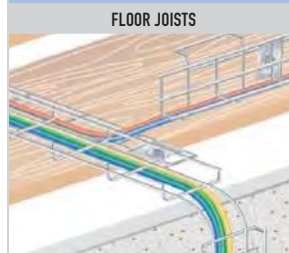

RESIDENTIAL APPLICATIONS

