

DST660



Display size
40"-60"



Max load
125lb (57kg)

SMARTMOUNT.

Flat/Tilt Wall Mount with Media Device Storage

FOR 40" TO 60" DISPLAYS


Designed to hold a display and media device, the DST660 is the ideal low profile solution for digital signage applications. Featuring an open wall plate for easy outlet access, multiple tilt options and portrait/landscape orientation, this is one of the most versatile digital signage mounts. Smartly designed storage means easy access to the media device without having to remove the display.

*Designed with ease of service in mind,
the media storage device housed by the
DST660 can be serviced by a single person
without removing the display.*



Additional Features

- ✓ Adaptor plate compatible for VESA® patterns larger than 400 x 400mm
- ✓ Display can be mounted in portrait or landscape
- ✓ Accommodates media players up to 12" x 13" x 2.4"
- ✓ The media player can be removed from the bottom if replacement, repair or maintenance is necessary without having to remove the display
- ✓ Included security hardware deters tampering and loss

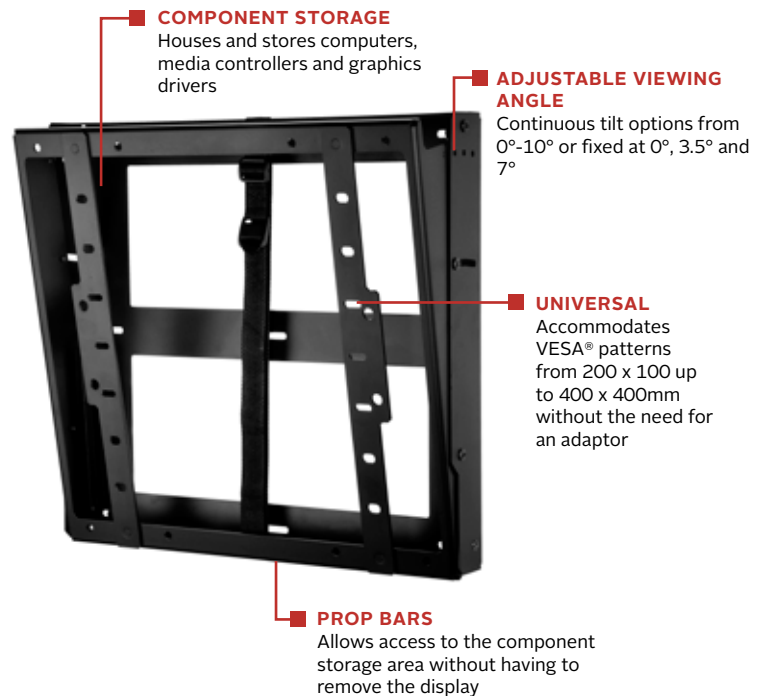

Clean profile hides
components from
view



Continuous
tilt from 0-10
degrees



Media device
access

RoHS  MADE IN 

DST660	SmartMount® Flat/Tilt Wall Mount with Media Device Storage				
--------	--	--	--	--	--

Product Specifications

	DIMENSIONS (W X H X D)	PRODUCT WEIGHT	LOAD CAPACITY	FINISH	AVAILABLE COLORS
DST660	18.50" x 17.16" x 2.83" (470 x 436 x 72mm)	10.7lb (5kg)	125lb (57kg)	Powder Coat	Black

Package Specifications


	PACKAGE SIZE (W x H x D)	PACKAGE SHIP WEIGHT	PACKAGE UPC CODE	PACKAGE CONTENTS	UNITS IN PACKAGE
DST660	27.00" x 18.25" x 5.50" (686 x 464 x 140mm)	15lb (7kg)	735029282945	Wall plate, adaptor bracket, adaptor rails, media strap and mounting hardware	1

Accessories

ACC-V800X: Adaptor accessory for 600 x 400 and 800 x 400mm mounting patterns

ADAPTER BRACKET DETAIL

All dimensions = inch (mm)

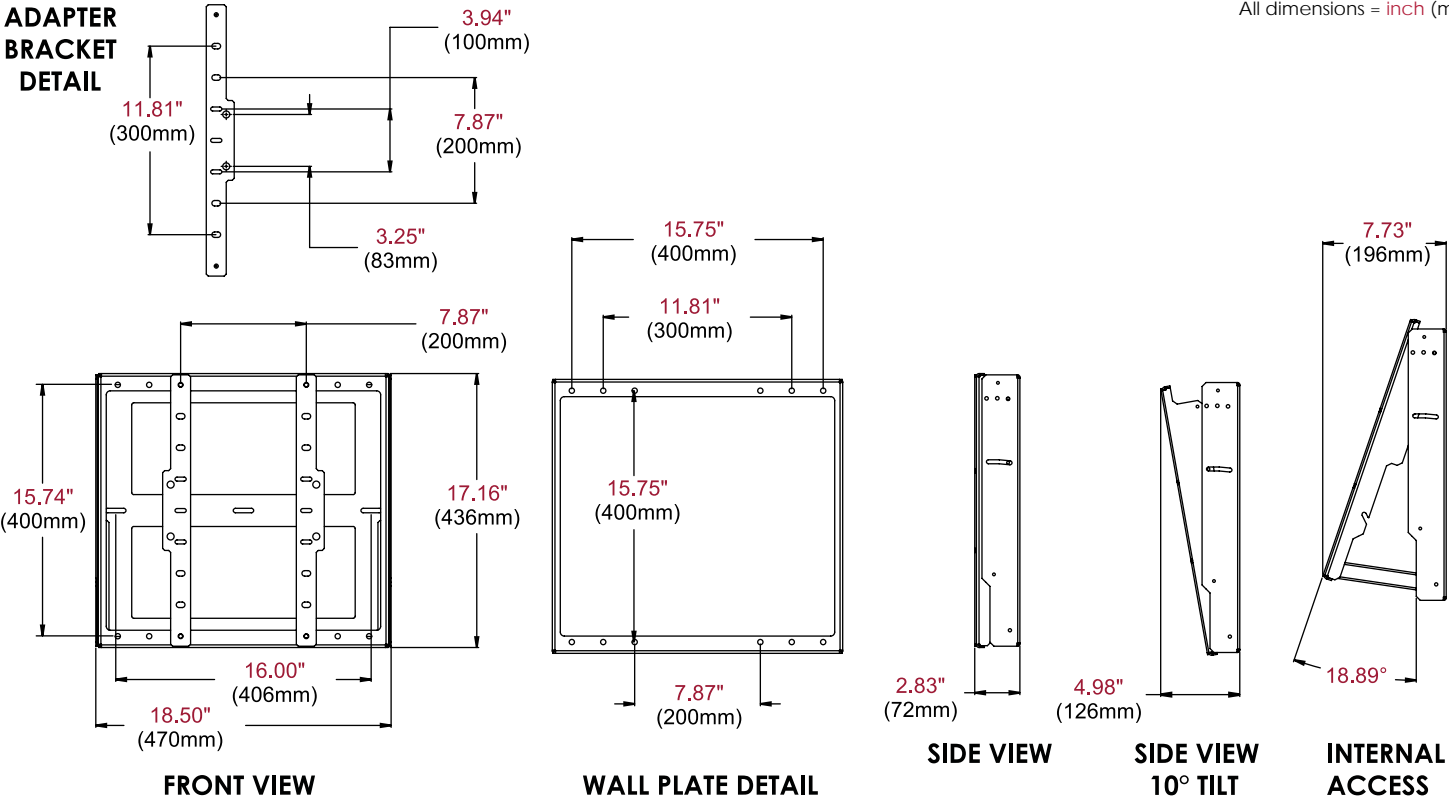

Architect Specifications

The SmartMount® Flat/Tilt Wall Mount with Media Device Storage shall be Peerless-AV model DST660 and shall be located where indicated on the plans. It shall be constructed of heavy gauge steel. The finish shall be scratch resistant black fused epoxy. Assembly and installation shall be done according to instructions provided by the manufacturer.

Visit peerless-av.com to see the complete line of AV solutions from Peerless-AV, including outdoor displays, wireless, kiosks, digital audio, display mounts, projector mounts, carts/stands, and a full assortment of accessories.

Peerless-AV
2300 White Oak Circle
Aurora, IL 60502 USA

(800) 865-2112
(630) 375-5100
Fax: (800) 359-6500

Peerless-AV Europe
Unit 3 Watford Interchange
Colonial Way, Watford
Herts, WD24 4WP
United Kingdom
+44 (0) 1923 200100
Fax: +44 (0) 1923 200101

Peerless-AV de México
Ave de las Industrias 413
Parque Industrial Escobedo
Escobedo, N.L.,
Mexico 66050
+52 (81) 8384-8300
Fax: +52 (81) 8384-8360

