



Compact Day/Night Fixed Camera featuring Super Dynamic 6 technology

Key Features

- **Super Dynamic 6** technology delivers 128x wider dynamic range compared to conventional cameras.
- High resolution: 650 TV lines
- High sensitivity with Day/Night function: 0.08 lx (Color), 0.008 lx (B/W) at F1.4. IR cut filter switches on/off to enhance the sensitivity in B/W mode.
- ABS (Adaptive Black Stretch) enhances visibility of dark area without degrading image quality in bright area.
- Focus Assist ensures easy installation.
- Various adjustment features including ATW (Auto Tracing White Balance) and ALC (Automatic Light Control)
- 16 axis matrix color compensation function enables wider range of natural color adjustment.
- 3-dimensional color conversion function for natural color reproduction even in lower color temperature situation
- Adaptive Digital Noise Reduction: Integration of 2D-DNR and 3D-DNR ensures noise reduction in various conditions.
- Electronic sensitivity enhancement: Auto (Up to 32x) / Manual (Up to 512x)
- Electronic shutter from 1/100 to 1/120,000 sec.
- Digital zoom: Up to 2x
- Auto Image Stabilizer for applications where vibration or wind is a concern
- Internal / Multiplexed Vertical Drive (VD2) synchronization
- Over the coaxial cable data communication

- 16 alphanumeric camera title display
- Multi language: English, French, Italian, Spanish, German, Russian, Chinese, Japanese
- On screen display menu
- ELC mode for easier lens adjustment upon installation
- Smart look fits for various applications such as shopping mall, hotels and hospitals.

Standard Accessories

• CD-ROM*.....	1 pc.	• Installation Guide.....	1 pc.
The following is used during installation procedures:			
• Power cord (only for WV-CP620) (Approx. 1.8 m (5.9 feet)).....	1 pc.		
• Power cord plug (only for WV-CP624P).....	1 pc.		
• Safety wire lug.....	1 pc.		
• Safety wire (Approx. 300 mm (1 feet)).....	1 pc.		
• Wire lug fixing screws (M2.5 x 8 mm (5/16 inches)).....	2 pcs. (including 1 for replacement)		
• Washer.....	1 pc.		
• Spring washer.....	1 pc.		
*The CD-ROM contains the operating installations and installation guide (PDF).			


Optional Accessories

<p>1/3 type 2x Varifocal Lens WV-LZA61/2S (3.8 ~ 8 mm) F1.4 (Wide) F1.8 (Tele)</p> 	<p>1/3 inch 8x Varifocal Lens WV-LZ62/8S (5 ~ 40 mm) F1.6 (Wide) F1.9 (Tele)</p> 
---	---


Specifications

TV System	WV-CP620	WV-CP624
Camera	1/3 type interline transfer CCD	
Effective Pixels	976 (H) x 494 (V)	
Scanning Mode	2:1 interlace	
Scanning Area	4.8 (H) x 3.6 (V) mm {3/16 inches (H) x 5/32 inches (V)}	
Scanning Frequency	Horizontal: 15.734 kHz Vertical: 59.94 Hz	
Horizontal Resolution	650 TV lines typ.	
Minimum Illumination	color mode	0.08 lx
	black-and-white mode	0.008 lx
Signal-to-Noise Ratio	52 dB (AGC: OFF)	
White Balance	AWC (2,000 ~ 10,000 K), ATW1 (2,700 ~ 6,000 K), ATW2 (2,000 ~ 6,000 K)	
Light Control	ALC/ALC+/ELC	
AGC	ON (LOW, MID, HIGH) / OFF	
Super Dynamic 6	ON / OFF	
Dynamic Range	52 dB typical (Super Dynamic 6 : ON)	
Electronic Shutter	OFF (1/60), 1/100, 1/250, 1/500, 1/1000, 1/2000, 1/4000, 1/10000, 1/120000 (s)	
Electronic Sensitivity UP	32x max. AUTO, 512x max. FIX	
Day & Night (IR)	AUTO1/AUTO2/ON/OFF	
Digital Noise Reduction	High or Low	
Scene File	2 patterns	
Video Motion Detection	OFF / MOTION DETECTION / SCENE CHANGE	
Privacy Zone	ON(1) / ON(2) / OFF	
Image Stabilizer	ON / OFF	
Camera Title	16 alphanumeric characters	
Synchronization	Internal (INT), multiplexed vertical drive (VD2)	
Input / Output	Video Output 1.0 V [p-p] NTSC composite video signal 75 Ω	
Controller Interface	Coaxial Multiplex System	
External I/O Terminals	Alarm IN 1pc, Alarm OUT 1pc	
General	Setup Method OSD setup menu	
Language	English, French, Italian, Spanish, German, Russian, Chinese, Japanese	
Safety / EMC Standard	UL (UL60065), FCC (Part 15 ClassA), C-UL (E60065), DOC (ICES-003)	
Power Source and Power Consumption	120 V AC 60 Hz 2.3 W	24 V AC 60 Hz: 2.5 W , 12 V DC: 220 mA
Ambient Operating Temperature	-10 °C ~ +50 °C (14 °F ~ 122 °F)	
Ambient Operating Humidity	90 % or less (without condensation)	
Dimensions	101 mm (L) x 72 mm (W) x 55 mm (H) {3-31/32 inches (L) x 2-27/32 inches(W) x 2-5/32 inches (H)}	81 mm (L) x 72 mm (W) x 55 mm (H) {3-3/16 inches (L) x 2-27/32 inches(W) x 2-5/32 inches (H)}
Mass (approx.)	Approx.190 g {0.42 lbf} (Power cord excluded)	Approx.170 g {0.35 lbf}
Finish	ABS resin / White Painting	

Part Names and Functions

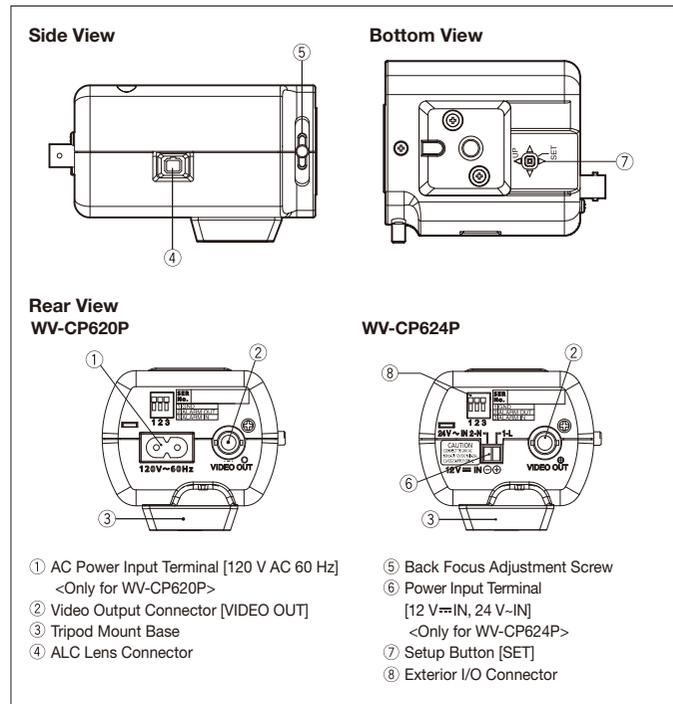

Appearance

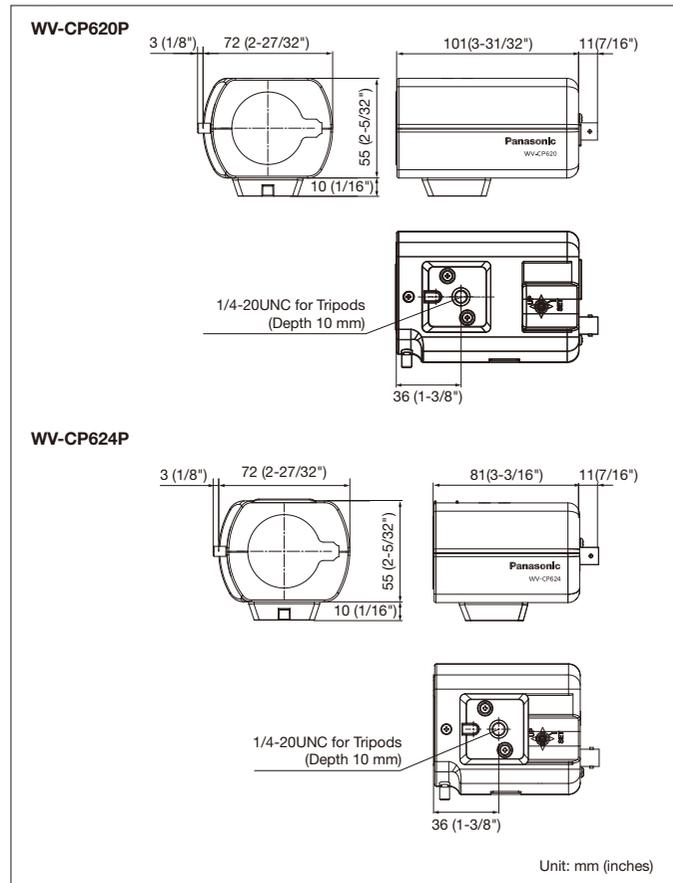

Important

- Safety Precaution: carefully read the operating instructions and installation manual before using this product.
- "Super Dynamic", "SDII", "SDIII", "SD5", "SD5Link", "SD6", "i-PRO" and "i-PRO SmartHD" logos are trademarks or registered trademarks of Panasonic Corporation.

- All TV pictures are simulated.
- Weights and dimensions are approximate.
- Specifications are subject to change without notice.
- These products may be subject to export control regulations.
- All product pictures are NTSC models.

DISTRIBUTED BY:

Panasonic[®]

<http://panasonic.net/security/>

Printed in Japan (2A-097L)