

**DESCRIPTION:**

The JO Series is a 1 x 2 system which features a 7" screen with electrostatic touch buttons and door release. The JO master and expansion station is less than an inch thick and allows VOX or PTT communication. The JO Series is available in three easy to install kits, each featuring a single master station, a power supply, and one of three different door stations.

The JOS-1A kit includes the JO-DA surface mount plastic door station. The JOS-1V kit features the JO-DV surface mount door station with a zinc die cast faceplate. The JOS-1F kit contains the JO-DVF flush mount door station with a stainless steel faceplate.

The JO-1MD master station is included in all kits and the JO-1FD expansion station can be purchased separately. The system connects easily using 2-conductor to the door station and 6-conductor between internal stations.


**JO FEATURES:**

- 7" Screen
- Slim design
- Hands-free communication
- Electrostatic touch buttons
- VOX or PTT Communication
- Available internal expansion unit
- Simple 2 wire connection to door
- Kits to ensure correct system configuration

# JO-1FD

## JO Expansion Station

### FEATURE CALL-OUT:

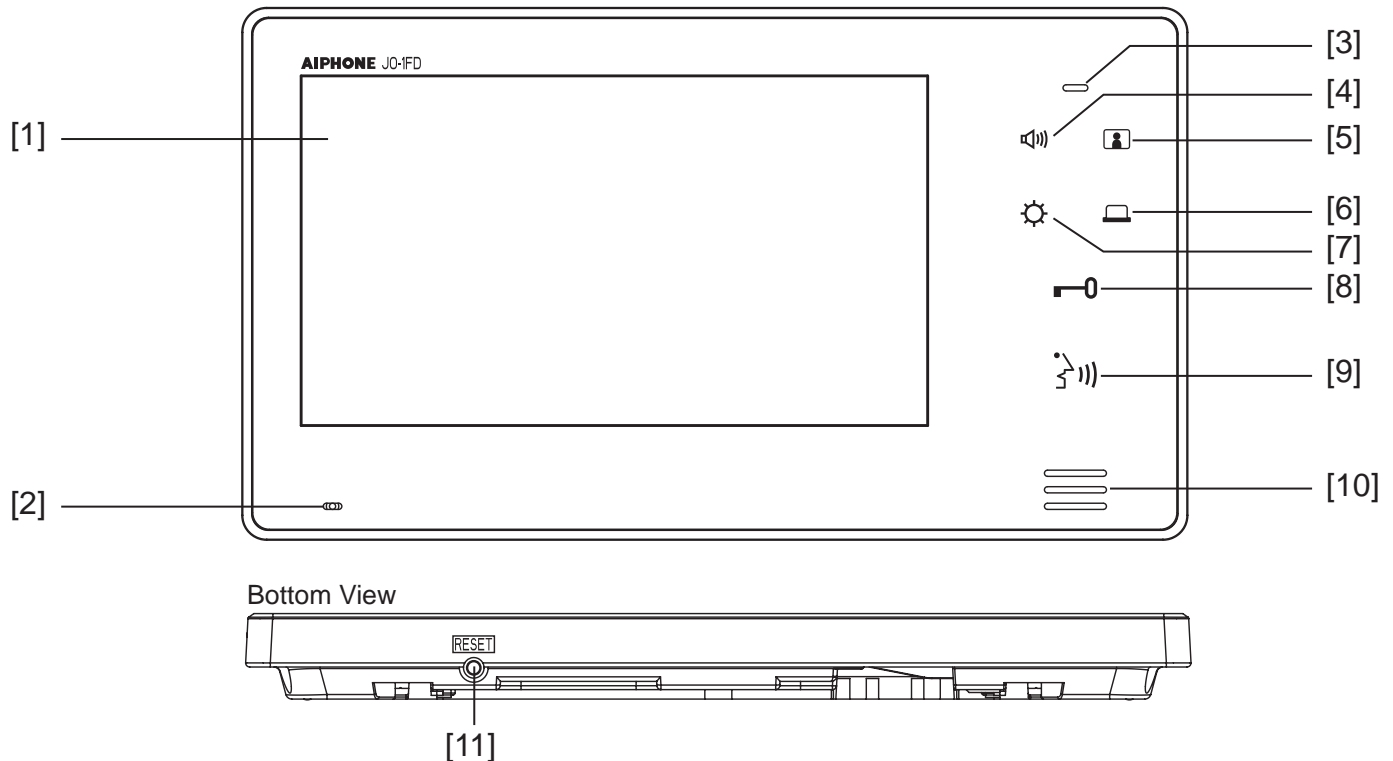

### FEATURE CALL-OUT DEFINITIONS:

- [1] Color LCD screen
- [2] Microphone
- [3] Status LED
- [4] Volume control button
- [5] Monitor button
- [6] Option button
- [7] Screen brightness control
- [8] Door release button
- [9] Talk/Off button
- [10] Speaker
- [11] Reset button

### SPECIFICATIONS:

Power source:	18V DC (PS-1820UL)
Current consumption:	Max. 420mA
Dry contacts:	N/O 24V AC/DC, 500mA
Communication:	
Hands-free:	Auto-voice actuation
PTT:	Press-to-talk, release to listen
Monitor:	7 inch TFT color LCD
Mounting:	Wall mount
Electrical box:	3-gang box
Material:	Flame resistant ABS resin
Color:	White
Temperature:	32°F - 104°F (0-40°C)
Dimensions:	5-1/8" H x 9-1/16" W x 13/16" D
Weight:	Approx. 1.06lbs (480g)