

**DESCRIPTION:**

The JP-4MED is a video master station with a 7" color touchscreen LCD. The JP-4MED offers handset (duplex) and hands-free (VOX) communication. This unit will support up to 4 door stations and 8 inside stations. All inside stations are equipped with a door release button for the user to allow visitor entry.

The JP-4MED is also equipped with PTZ and brightness controls, giving the user control of the door station camera angle and camera lighting for better visibility. Picture memory records up to 20 calls to internal memory and 1,000 calls to a removable SD / SDHC card (not included).

The JP-4MED connects to door stations using 18AWG, 2 conductor cable and connects to sub master stations using CAT-5e or CAT-6 cable.


**JP-4MED FEATURES:**

- 7" color touchscreen LCD
- Hands-free (VOX) or handset communication
- Camera position and zoom can be set for call-in
- Video out via supplied connector
- Picture Memory
  - Internal: 20 calls
  - SD / SDHC: 1,000 calls
- Door release button
- Optional service button
- Security inputs for alerting stations
- PTZ and brightness control
- Selectable call tones (8)
- Station partitioning with security code
- All Call to inside stations
- Door monitoring
- Continuous room monitoring

# JP-4MED

## Master Station

### FEATURE CALL-OUT:

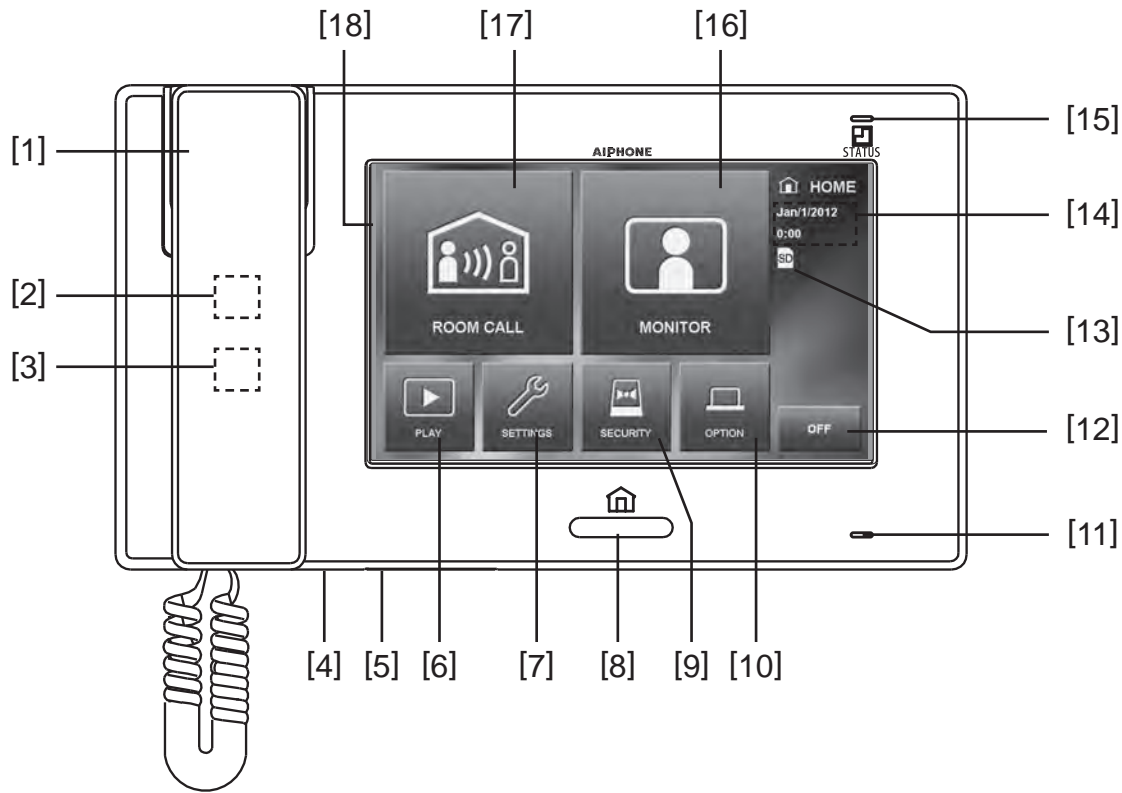

### FEATURE CALL-OUT DEFINITIONS:

- [1] Handset
- [2] Speaker
- [3] Hearing aid T-mode symbol
- [4] Reset button
- [5] SD / SDHC card slot
- [6] Play button (touchscreen)
- [7] Settings button (touchscreen)
- [8] Home button
- [9] Security button (touchscreen)
- [10] Option button (touchscreen)
- [11] Microphone
- [12] Off button (touchscreen)
- [13] SD card installed symbol
- [14] Current date and time
- [15] Status LED
- [16] Monitor button (touchscreen)
- [17] Room call button (touchscreen)
- [18] Color touchscreen LCD

### SPECIFICATIONS:

Power Source:	24V DC - use PS-2420UL
Consumption:	340mA (max)
Communication:	
Handset	Simultaneous communication
Hands-free	Auto-voice actuation
Monitor:	7" TFT color touchscreen LCD
Pixels:	800 x 480
Picture memory:	Internal: 20
	External: 1,000 using
	SD / SDHC card (not included)
Picture protect:	Internal: 5
	External: 100
Mounting:	Surface wall mount or
	desk mount using MCW-S/A
	(sold separately)
Temperature:	32-104°F (0-40°C)
Dimensions:	5-11/16" H x 10-1/16" W x 1-7/8" D
Weight:	Approx. 1.74 lbs (790g)