




Now available in durable Black zinc plating.

FEATURES

- Designed with a 1/4" x 20 threaded bolt compatible with US Standard tools.
- Use SWK to splice any two sections of Cablofil tray.
- Swaged nut allows clamp to be stationary while nut is tightened
- Consult chart below for correct number of SWK sets needed for each width of tray
- Also use for fabricating bends, turns and tees
- UL Classified Splice

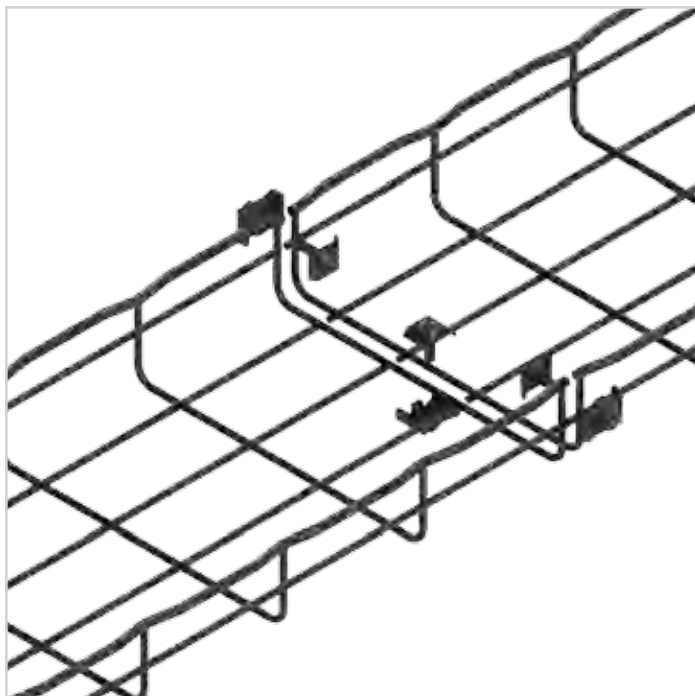

 CF30 – CF54 – CF105 – CF150 – TFX35 – CFG	 2" (50 mm)	 4" → 8" (100 → 200 mm)	 12" → 24" (300 → 600 mm)
 SWK attachment sets needed for side wires	2x SWK	2x SWK	2x SWK
 SWK attachment sets needed for bottom wires	–	1x SWK	2x SWK

	PKG. QTY.	WEIGHT		EZ	DC	316L	BL
		LBS	KG				
SWK	50	3.6	1.6	943 215	943 216	943 218	943 217

FINISHES		
SYMBOL	MATERIAL	FINISH & STANDARD
EZ	Carbon Steel	Electrozinc: Electrozinc plating ASTM B 633
DC	Carbon Steel ASTM A510 Grade 1008	Geomet: Zinc and Aluminum Protection / Equivalent to Hot Dip Galvanization / ASTM F 1136
316L	Stainless Steel AISI Type 316L	Stainless Steel 316L: Cleaned and Passivated ASTM A 380
BL	Carbon Steel ASTM A510 Grade 1008	Black Painted: Black Powder Coated ASTM D 3451

Legrand/Cablofil
 8319 State Route 4
 Mascoutah, IL 62258 USA
 1-800-658-4641
 618-566-3230
 Fax 618-566-3250
www.legrand.us/cablofil