

CE-VX30(B) Vandal X True D/N IR Dome Camera + Heaters



CE-VX50 (White)
<<<




CE-VX50B (Black)




INFO:

- 1/3" SONY Super HAD II CCD (960H)
- 700 TVL Resolution
- 2.8-12mm (f1.4) True D/N Lens
- 6 High Output IR LEDs
- IR Shield Technology
- NX4 Digital Signal Processor
- OSD Menu Control via Built-in Joystick or CE-REMOTE/UTC
- 3 Axis Adjustment
- Built-In Heaters
- IP68 Weather Rated
- DC12V/AC24V
- UL Listed

DIMENSIONS:

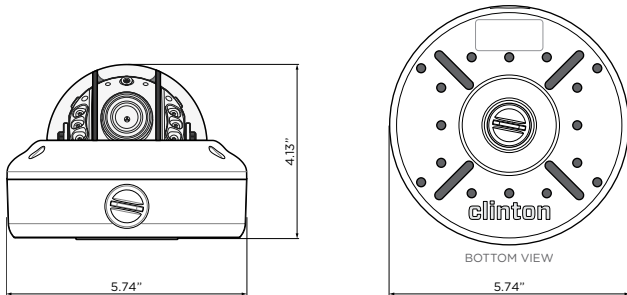

MOUNTS TO:

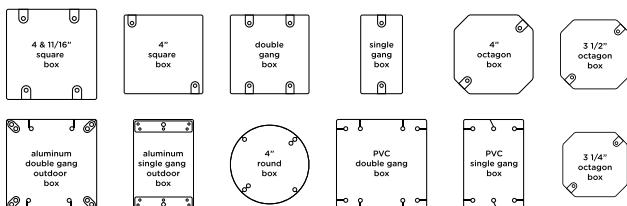

SPECIFICATIONS:

Camera	
Image Sensor	1/3" SONY Super HAD II CCD (960H)
Resolution	700 TVL
Effective Pixels	976 (H) x 494 (V)
Scanning System	2:1 Interlace
S/N Ratio	52dB (AGC Off)
Sync System	Internal / Line Lock
Minimum Illumination	0.15 Lux (Color), 0.0006 Lux (Sens-Up) 0 Lux w/ IR LEDs
Shutter Speed	Auto / Manual (1/60, 1/50 - 1/100,000)
Dynamic Range	N/A
Lens	2.8-12mm (f1.4) True D/N Lens
Filed of View	92° - 28° (Horizontal)
Video Output	1.0 Vp-p, 75Ω
Power Consumption	DC12V: 810mA (Max.) AC24V: 300mA (Max.)
Frequency	Horizontal: 15.734 KHz, Vertical: 59.94 Hz
Power Requirement	DC12V / AC24V
Operating Temperature	-40°F - 122°F / -40°C - 50°C
Operating Humidity	95% RH Max.
Weather Rating	IP 68
IR LEDs	6 IR LEDs - High Output
Heaters/Fan	Heaters
Materials	Aluminum Case w/Polycarbonate Dome
Dimensions	5.74" (Dia.) x 4.13" (H) / 145.8mm (Dia.) x 104.9mm (H)
Weight	2.75 lbs / 1,247g
OSD	
DSP Type	S7
Menu Control	OSD Menu Control via Built-In Joystick or CE-REMOTE
Exposure	Brightness, Shutter, AGC
Sens-Up	Yes (x2 - x64)
White Balance	ATW, AWB, AWC-Set, Manual
Digital Dynamic Range	Yes
Backlight Control	BLC, HLC, WDR
Day/Night	Auto, Color, B&W, External
Noise Reduction	3DNR
Camera Title/ID	N/A
Sync	N/A
Monitor	View Angle (4:3 / 16:9)
Motion Detection	(Intelligent) 4 Zones
Privacy Masking	15 Zones
Digital Image Stabilization	N/A
Dead Pixel Control	N/A
Digital Effects	Digital Zoom, D-WDR, Defog, Image Flip
Languages	English, Chinese, Japanese, Korean
Other	Sharpness, Gamma, Pedestal, Color Gain
ACCESSORIES	
CE-REMOTE	Plug in OSD remote
CE-VXWB(B)	Wall Bracket (White or Black)
CE-VXAP(B)	Adapter Plate for Wall Bracket
CE-VXDC(B)	Deep Case. Additional 1.1" of space. (White or Black)
CE-VXPC	Pendant Cap. Mounts to poles or conduit.
CE-VXDPC	Deep Pendant Cap. Additional 1.1" of space.
CE-VXRM(B)	Recess Mount (White or Black)

CERTIFICATIONS:

