 


## Una All-in-One Recorder exacqVision **LC-Series**





- **All-in-One Recorder - Easiest to Quote, Install & Service**
  - 8 or 16 PoE+ camera ports, No external Ethernet switch required
  - Includes 8 or 16 exacqVision START licenses (*upgradeable to Pro or Enterprise*)
  - Up to 12TB of video storage for up to 16 IP cameras
  - Unlimited scalability by adding more recorders

- **Camera Power Management**
  - Monitor and control camera power usage in exacqVision client, no separate switch management software required
  - Save maintenance trips by remotely power cycle individual POE+ cameras
  - High output power supply provides up to 25 watts per camera, 120 watts per 8 cameras, 240 watts per 16 cameras

- **Easy Connect**
  - Simply plug in and record; automatically configures IP cameras for motion-based recording
  - Easily connect to supported IP cameras

- **View Video Anywhere with Free Client Software**
  - View and manage servers from Windows/Linux/MAC PCs with free client software
  - View live and recorded video in any browser
  - View live and recorded video on iOS, Android or Windows Phone 8 mobile devices with free application

- **3-Year Warranty & Software Updates**
  - Includes a 3-year hardware warranty and technical support
  - 3 years of unlimited software updates to constantly increase the functionality of your exacqVision recorder

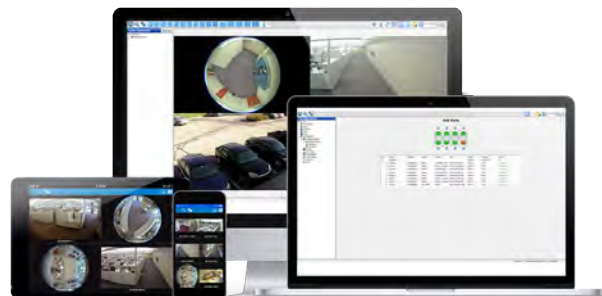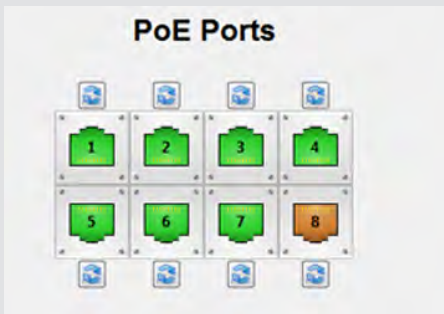

IP	
Maximum IP Cameras	8 or 16
Included IP Licenses	8 or 16
PoE+ Camera Ports	8 or 16
Maximum Camera Power	25 watts per port max 120 watts (8 port)/240 watts (16 port)
SERVER	
Pre-Loaded VMS Software	Start(standard), Professional, Enterprise (optional)
Typical Video Storage Rate (Mbps)	150Mbps
Local Client Display Rate (FPS)	270 FPS
Maximum Hard Drives	2
Maximum Storage	12 TB
Monitor Output	HDMI, VGA
Operating System	Ubuntu Linux 14.04
CPU	Intel Celeron
RAM	4 GB
NIC	1x1 Gbps
USB	8 x USB (2 front, 6 rear)
Keyboard & Mouse	Included
GENERAL	
Dimensions	10.9" x 16.9" x 3.5" 27.7 x 42.9 x 8.9cm
Weight	14 lbs. 6.4 kg
Regulatory	UL-Listed, CE
Input Voltage	100/200 VAC auto-sensing
Operating Temperature	40° - 95° F 4.5° - 35° C

## Related Products



exacqVision VMS Software



Exacq Mobile App

[www.exacq.com](http://www.exacq.com)