


Deadlocks

D660 Series Grade 1

(SFIC sold less core)



D660 626

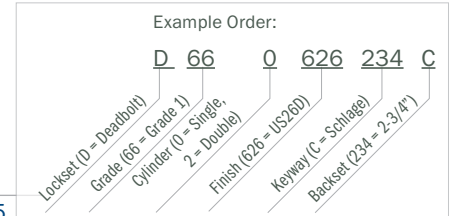

Part#	Finish	Keyway	Backset	Function	CLK#
D660 626 234 C	US26D	SCHL C	2-3/4"	Single	cs359455
D660 626 234 IC	US26D	SFIC	2-3/4"	Single	cs359456
D662 626 234 C	US26D	SCHL C	2-3/4"	Double	cs359446
D662 626 234 IC	US26D	SFIC	2-3/4"	Double	cs359447

D160 Series Grade 2

(SFIC sold less core)



D160 626



D160 613



D160 605

Part#	Finish	Keyway	Backset	Function	CLK#
D160 605 6WL C	US3	SCHL C	6-way adj.	Single	cs257037
D160 605 6WL C 5P KA4	US3	SCHL C*	6-way adj.	Single	cs477954
D160 605 6WL IC	US3	SFIC	6-way adj.	Single	cs359448
D160 609 6WL C	US5	SCHL C	6-way adj.	Single	cs473505
D160 613 6WL C	US10B	SCHL C	6-way adj.	Single	cs257038
D160 613 6WL IC	US10B	SFIC	6-way adj.	Single	cs359449
D160 626 6WL C	US26D	SCHL C	6-way adj.	Single	cs257039
D160 626 6WL IC	US26D	SFIC	6-way adj.	Single	cs359450
D160 630 6WL C	US32D	SCHL C	6-way adj.	Single	cs103126
D160 630 6WL IC	US32D	SFIC Prep	6-way adj.	Single	cs103129
D162 605 6WL C	US3	SCHL C	6-way adj.	Double	cs257031
D162 605 6WL C 5P KA4	US3	SCHL C*	6-way adj.	Double	cs477956
D162 605 6WL IC	US3	SFIC	6-way adj.	Double	cs359437
D162 609 6WL C	US5	SCHL C	6-way adj.	Double	cs485779
D162 613 6WL C	US10B	SCHL C	6-way adj.	Double	cs257032
D162 626 6WL C	US26D	SCHL C	6-way adj.	Double	cs257033
D162 626 6WL IC	US26D	SFIC	6-way adj.	Double	cs359439
D162 630 6WL C	US32D	SCHL C	6-way adj.	Double	cs103130
D162 630 6WL IC	US32D	SFIC Prep	6-way adj.	Double	cs103132

* 5-pin, Keyed-Alike 4


Parts & components found on pages 35 & 36.

Door Thickness Specifications	
Series	Inches
D660 C	1-9/16" to 2"
D662 C	1-9/16" to 2"
D660 IC	1-9/16" to 2"
D662 IC	1-9/16" to 2"
D160 C	1-3/8" to 1-3/4"
D162 C	1-3/8" to 1-3/4"
D160 IC	1-9/16" to 2"
D162 IC	1-9/16" to 2"

Features:

- ANSI A156.36 Grade 2 (D160), Grade 1 (D660), UL Listed 3-hour
- 25 year mechanical warranty, 5 year finish warranty
- Solid brass cylinder, drilled 6, pinned 6 unless noted
- Case Qty: 20

Finishes:

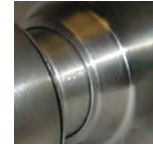

630
U.S. = US32D
Satin Stainless Steel



626
U.S. = US26D
Satin Chrome



613
U.S. = US10B
Dark Bronze, Oil Rubbed



609
U.S. = US5
Antique Brass



605
U.S. = US3
Bright Brass

NVRPOE Series 1080P NVRs



Northern 4, 8 & 16 Channel 1080p NVRs with Built-in POE

- Real-Time 30FPS/Ch Recording @ 1080p
- Up to 6MP Recording
- H.264 Recording Compression
- Full Mobile Apps for iPhone, iPad & Android
- Built-in Motion Detection/Privacy Mask
- Free DDNS, CMS & Streaming Server Software
- Supports P2P Operation
- Integrated 50W/120W/200W PoE Switch (4/8/16Ch)
- Included Mouse & IR Remote
- Dual USBs for Copying Video & Mouse Control
- Simultaneous HDMI & VGA Video Outputs
- Up to 16 Channel Synchronous Playback
- Accepts ONVIF/PSIA Protocols
- Rack Mount Hardware Included (8 & 16Ch)
- PAL/NTSC Selectable
- Built-in Audio & Alarm
- Supports 2-Way Audio



Guarding Expert
Mobile App

Plug & Play
with Northern IP Cameras

Up To 12TB Available Storage

Part#	CLK#	Channels	HDD Size
NTH-NVR4POE2T	cs106752	4	2TB
NTH-NVR8POE2T	cs106758	8	2TB
NTH-NVR16POE2T	695860	16	2TB

IP3 Series Camera Features

All IP3 Series Camera Feature

- Full HD 1080p / 720p Real Time Video
- Up to 3MP (2048x1536) Resolution @ 15FPS
- PoE, D-WDR, DNR, IP66
- Free CMS & IP Server Software
- ONVIF / PSIA / CGI Compliant
- UL/CUL Certified



IP3 Series Cameras

3MP IP Outdoor IR Bullet Camera

- 4mm IR Lens w/ IR Cut Filter
- 30 IR LED's - 65' IR Range



Part#	CLK#	Description
NTH-IP3B	cs106733	3MP IP Bullet

3MP IP Outdoor IR Dome Camera

- 2.8mm Wide Angle IR Lens w/ IR Cut Filter
- 30 IR LED's - 100' IR Range
- Micro SD Card Slot (Card Sold Separately)



NTH-IP3D	Call to Order	3MP IP Dome
----------	-------------------------------	-------------

3MP IP Outdoor IR Turret Camera

- 2.8mm Wide Angle IR Lens w/ IR Cut Filter
- High Power LED - 100' IR Range



NTH-IP3T	cs106734	3MP IP Turret
----------	--------------------------	---------------

3MP IP Outdoor IR Wedge Camera

- 2.8mm Wide Angle IR Lens w/ IR Cut Filter
- 10 LED's - 30' IR Range
- Micro SD Card Slot (Card Sold Separately)



NTH-IP3W	cs106736	3MP IP Wedge
----------	--------------------------	--------------

3MP IP Varifocal Outdoor IR Bullet Camera

- 2.8~12mm IR Lens w/ IR Cut Filter
- 42 LED's - 100' IR Range
- Micro SD Card Slot (Card Sold Separately)
- Junction Box Included



NTH-IP3VFB	cs106741	3MP Varifocal Bullet
------------	--------------------------	----------------------

3MP IP Varifocal Outdoor IR Dome Camera

- 2.8~12mm IR Lens w/ IR Cut Filter
- 24 LED's - 65' IR Range
- Micro SD Card Slot (Card Sold Separately)



NTH-IP3VFD	cs106737	3MP Varifocal Dome
------------	--------------------------	--------------------

To Order Call CLARK Security at: 1-844-522-5275