



The 9600 series is a windstorm-rated, surface mounted electric strike designed to accommodate rim exit devices with a 3/4" throw Pullman latchbolt. All components are completely encased within its 3/4" thick stainless steel housing, so no cutting on the frame is required for installation. Simply place the electric strike on the surface of the frame, align it with the exit latchbolt and install. Adjustments have never been easier as the base is now separate from the cover. It is field selectable for fail secure or fail safe operation, and for 12 or 24 VDC.

The 9600 is the only surface mounted electric strike designed with the strength and durability required to exceed the severe forces of ANSI Windstorm testing.

9600 Series

The stylish windstorm-rated, surface mounted solution

Specifications

- UL listed to ANSI 250.13-2003 Severe windstorm listed
- Florida Building Code Approved (FL#14307)
- UL 1034 burglary-resistant listed and suitable for outdoor use
- UL 294 (6th Edition) listed
- ANSI/BHMA, A156.31 Grade 1
- Environmental Product Declaration

- RoHS compliant
- Patents: 6,390,520; 8,454,063 and patent pending

Frame Application


- Metal
- Wood

Electrical (continuous duty)

- .45 Amps at 12 VDC
- .25 Amps at 24 VDC

9600 Models

9600	Universal electric strike	
RF-9600	Integrated Prox	Includes the strike body, Prox reader and door position switch
IC-9600	Integrated iCLASS®	Includes the strike body, iCLASS reader and door position switch

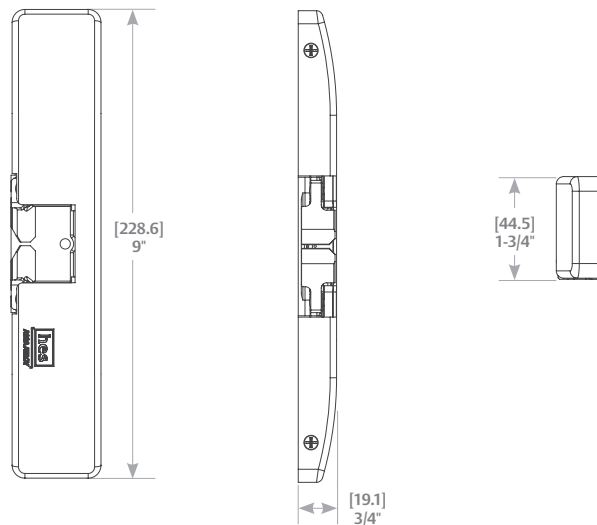

Standard Features

- Installs in metal or wood frames
- Wood screws not provided
- Separate base and decorative cover for easy adjustments
- Stainless steel construction
- Tamper-resistant
- Static strength 2,000 lbs.
- Dynamic strength 120 ft-lbs.
- Endurance 1,000,000 cycles
- Field selectable fail secure/fail safe
- Dual-voltage 12 or 24 VDC
- Horizontal adjustment
- Non-handed
- Internally mounted solenoid
- Accommodates up to 3/4" Pullman latch
- Five-year limited warranty

*Independently verified by a nationally recognized testing laboratory.

Optional Features

- LBM** » Latchbolt monitor
- LBSM** » Latchbolt strike monitor

Accessories

- 9000-108** » Spacer plate (black or 630 finish)
- 9000-MTK** » Metal template kit
- SMB** » Surface mounting box
- 2001M** » Plug-in bridge rectifier
- 2004M** » ElectroLynx® adapter
- 2005M3** » SMART Pac® III
- 2006M** » Plug-in buzzer

Finishes

- 630** » Satin stainless steel
- 605** » Bright brass
- 606** » Satin brass
- 612** » Satin bronze
- 613** » Bronze toned
- 613E** » Dark oxidized satin bronze
- 629** » Bright stainless steel



RIM EXIT DEVICES



FIELD SELECTABLE
(12 OR 24VDC)



FIELD SELECTABLE
(FAIL SECURE /
FAIL SAFE)



GRADE 1



OUTDOOR
RATED



UL 1034
BURGLARY
LISTED



ANSI A250.13-2003
WINDSTORM
RESISTANT

hes
ASSA ABLOY