

32" LED Monitor

HDMI, VGA & BNC Video Inputs, PC Audio In/Output



32"

SPECIFICATION	LED32
Video System	NTSC/PAL (Auto Sensing)
Max Resolution	1920x1080 (Native)
Supported Resolutions	720x400; 640x480; 800x600; 1024x768; 1280x1024; 1366x768; 1440x900; 1600x900; 1680x1050; 1920x1080
3D Comb Filter	Yes
3D De-Interlace	Yes
OSD (On Screen Display)	Yes
Backlight	LED
Active Display Area	32" Diagonal
Impedance	75 OHM Self Terminating
Video Input Signals	HDMI, VGA, Composite BNC
Aspect Ratio	Selectable 16:9 or 4:3 in OSD
Pixel Pitch	0.364mm
Color Depth	24 bits, 16.7 Million colors
Brightness	300 cd/m2
Contrast Ratio	3000:1
Viewing Angle (H/V)	178°/178°
Response Time	6.5ms
Auto Adjustment	Yes
Certificates	CE, FCC, UL
Languages	English, Chinese, German, French, Spanish, Italian
Input Voltage	100 ~ 240V AC
Power Consumption	<55W
Video Connections	HDMI, VGA, BNC 1 Input, BNC 2 Input/Output
Audio Connections	PC Audio (3.5mm Stereo) for VGA & BNC Input
Speakers	8Ω, 3 Watt per Channel
Dimensions (with stand) (H x W x D)	20.63" x 29.13" x 7.75"
Weight	17.6 lb
Vesa Mounting	Yes (200 x 100)
Operating Temperature	32° ~ 104°(0°C ~ 40°C)

Note: Specification subject to change without notice


FEATURES

- ◆ 16:9 Aspect Ratio
- ◆ 1920 x 1080 Max Resolution
- ◆ Super Fast 6.5ms Response Time
- ◆ LED Backlight
- ◆ Built-In Power Supply
- ◆ 3D Comb Filter & 3D De-Interlace
- ◆ Included IR Remote Control
- ◆ Includes 6' HDMI & VGA Cables
- ◆ 3D Digital Noise Reduction
- ◆ HDMI & VGA Inputs
- ◆ Looping BNC Input
- ◆ PC Audio Input/Output
- ◆ Low Power Consumption
- ◆ Full OSD Control of All Monitor Functions
- ◆ Vesa Mounting (200 x 100)
- ◆ CE, FCC, UL Certifications

INCLUDED ACCESSORIES


1. 6' HDMI Cable
1. 6' VGA Cable
1. 3.5mm PC Audio Cable
1. Power Cord
1. User Manual
1. IR Remote Control

REAR PANEL CONNECTIONS

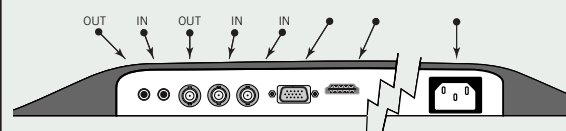

Monitor Dimensions:

LED32

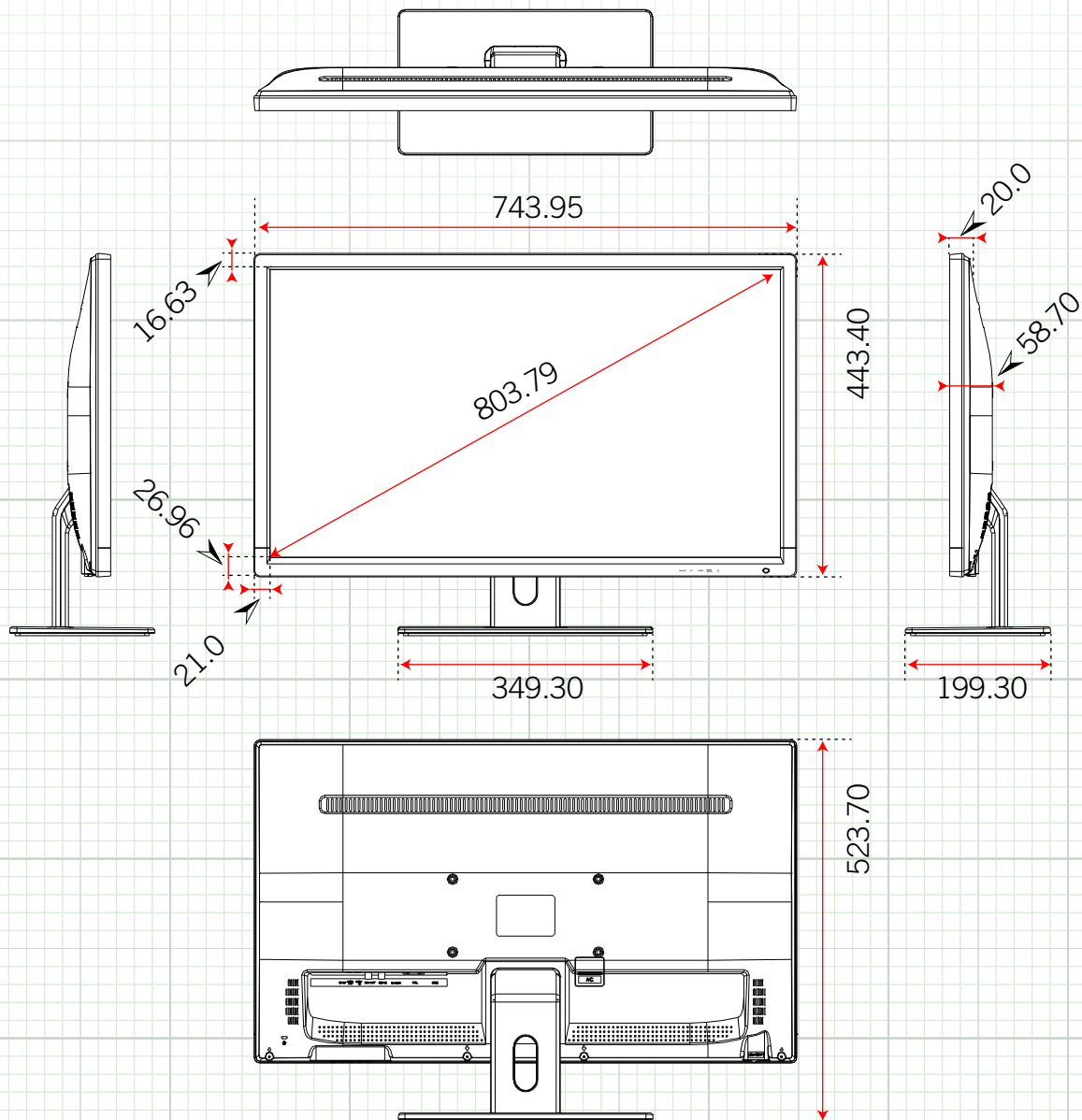

Note: Specification subject to change without notice