

12VDC1AMP 1 Amp 12 Volt DC Power Supply

FEATURES

- ◆ 1Amp Output
- ◆ Class II Transformer
- ◆ UL Listed



12VDC2AMP 2 Amp 12 Volt DC Power Supply



FEATURES

- ◆ 2Amp Output
- ◆ Class II Transformer
- ◆ UL Listed



SPECIFICATION	12VDC1AMP	12VDC2AMP
Type	Class II, UL Listed	Class II, UL Listed
Input	AC 100-240V 50/60HZ 0.3A MAX	AC 100-240V 50/60HZ 0.5A MAX
Output	12VDC 1Amp (Regulated)	12VDC 2Amp (Regulated)
Misc	Center Pin Positive	Center Pin Positive
Dimensions (W x H x D)	26mm x 73mm x 45mm (62 w/plug)	32mm x 73mm x 62mm (78 w/plug)

12 Volt DC Power Connectors

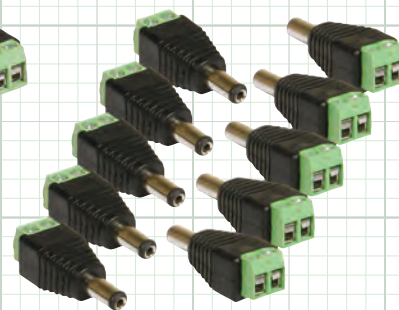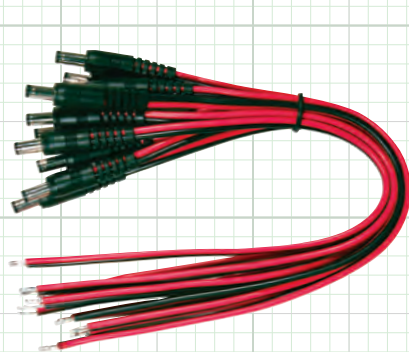

SPECIFICATION	12VDCCORD10PK	12VDCCON10PKF	12VDCCON10PKM
Description	DC Male with 12" Bare Lead Connection	DC Female with Screw Terminal Connection	DC Male with Screw Terminal Connection
Polarity	Center Pin Positive	Center Pin Positive	Center Pin Positive
Packaging	10 Pack	10 Pack	10 Pack

Note: Specification subject to change without notice