

SMT-2233

22" Wide LED Monitor




Key Features

- Support up to 1,920 x 1,080 resolution
- High contrast ratio 1,000 : 1
- Fast response time 5ms
- Video input : HDMI, VGA, BNC

Dimensions

Unit : mm (inch)

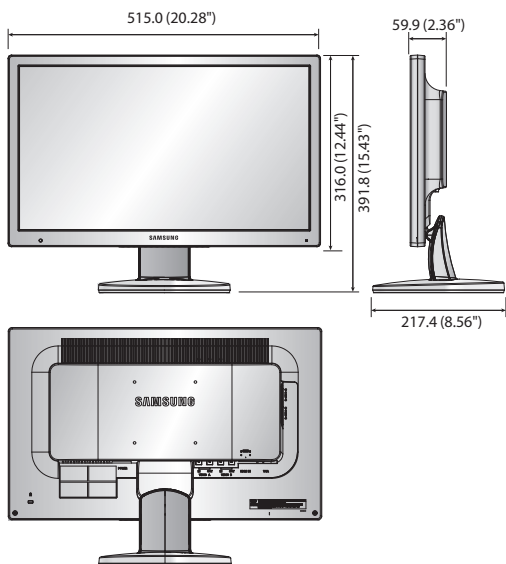

SMT-2233

DISPLAY		
Type	LED	
Screen Size	22"	
Max. Resolution	1,920 x 1,080	
Brightness	250cd/m ²	
Contrast Ratio	1,000 : 1	
Aspect Ratio	16 : 9	
Viewing Angle (H/V)	170° / 160°	
Display Color	16.7million	
Response Time	5ms	
Video System	NTSC / PAL	
Panel Life	30,000 hours	
Filter Type	3D combfilter	
INTERFACE		
Video	Connector	BNC type (2 in / 2 out)
	Connector	1 Analog RGB 15-pin D-sub
	Input Signal	0.7Vpp ±5%
VGA	Available Format	720 x 400@70Hz
		640 x 480@60Hz/72Hz/75Hz (VGA)
		800 x 600@56Hz/60Hz/72Hz/75Hz (SVGA)
		1,024 x 768@60Hz/70Hz/75Hz (XGA)
		1,152 x 864@75Hz
		1,280 x 960@60Hz
		1,280 x 1,024@60Hz/75Hz (SXGA)
HDMI	Connector	1 HDMI input (Type A connector)
	Available Format	640 x 480p@60Hz, 720 x 480i@60Hz, 720 x 480p@60Hz 720 x 576i@50Hz, 720 x 576p@50Hz, 1,280 x 720p@50Hz/60Hz 1,920 x 1,080i@50Hz/60Hz, 1,920 x 1,080p@50Hz/60Hz
Audio	Connector	2 RCA type (2 Stereo inputs)
	Output Signal	Speakers : 2 x 1W
Application Support	Remote controller	
ON SCREEN DISPLAY		
Functions	VESA™ DPM compatible	
Language	English, Spanish, French, German, Italian, Portuguese, Russian, Swedish, Turkish, Thai, Chinese, Japanese, Korean, Dutch, Danish, Arabic	
GENERAL		
Electrical	Input Voltage	100 ~ 240V AC (50/60Hz)
	Power Consumption	Max. 24W
Environmental	Operating Temperature	0 ~ +40°C (+32°F ~ +104°F)
	Operating Humidity	20% ~ 90% (Non-condensing)
Mechanical	Dimensions with Stand (WxHxD)	515.0 x 391.8 x 217.4mm (20.28" x 15.43" x 8.56")
	Dimensions without Stand (WxHxD)	515.0 x 316.0 x 59.9mm (20.28" x 12.44" x 2.36")
	Weight	5.18Kg (11.42 lb)
	Protection Glass	Yes
	Cabinet Color	Black
Wall Mounts	Optional	
VESA Mounts Interface	100 x 100mm (3.94" x 3.94")	

* The latest product information / sepecification can be found at <http://security.hanwhatechwin.com>