

600-lb Electromagnetic Locks



E-941SA-600

UL Listed

E-941SA-600PQ

With bond sensor, status LED, UL listed

Features:

- 600-lb Holding force
- Anodized aluminum housing (US 28)
- Selectable 12/24 VDC operation
- No residual magnetism
- MOV surge protection
- Adjustable mounting bracket
- Complete mounting hardware for typical installations
- "L" and "Z" brackets available for easy mounting
- Detachable faceplate

E-941SA-600PQ Only:

- Built-in dual-colored status LED and bond sensor to indicate locking status

Green	Door is closed and locked
Red	Door is not closed and/or locked
Off	Door in use / No power


- Bond sensor relay rated 3A@12VDC




E-941SA-600 shown

Dimensions:

Electromagnet

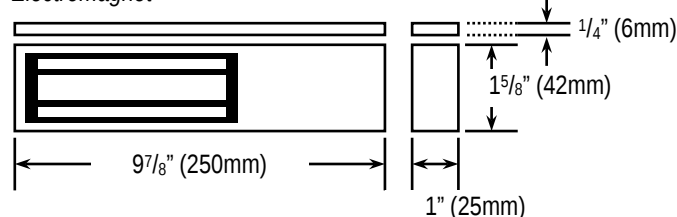

Armature Plate

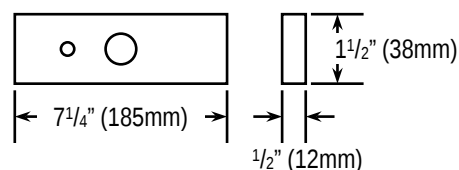

Also Available from SECO-LARM®:

Specifications:

Model	E-941SA-600	E-941SA-600PQ
Holding force	600-lb (272kg)	
Operating voltage	12/24 VDC $\pm$ 10%	
Current draw	12VDC	500mA@12VDC
	24VDC	250mA@24VDC
Operating temperature	14°~131° F (-10°~55° C)	
Weight	4-lb, 6-oz (2kg)	
Bond sensor relay		✓
Status LED		✓

	80-lb Mini Electromagnetic Locks	
	• E-941SA-80Q	80-lb Holding force
	300-lb Electromagnetic Locks	
	• E-941SA-300	Weatherproof
	• E-941SA-300RQ	Reversible
	1,200-lb Electromagnetic Locks	
	• E-941SA-1200	1,200-lb Holding force
	• E-941SA-1K2PQ	Bond sensor, LED
	• E-941SA-1K2PD	Bond sensor, LED, Timer

SECO-LARM® U.S.A., Inc.

16842 Millikan Avenue, Irvine, CA, 92606

Tel (CA & Int'l): (949) 261-2999 | (800) 662-0800

Website: www.seco-larm.com | Email: sales@seco-larm.com



Copyright 2015 © SECO-LARM U.S.A., Inc. All rights reserved.
All trademarks are the property of SECO-LARM U.S.A., Inc. or their respective owners.
The SECO-LARM policy is one of continual development. For that reason, SECO-LARM reserves the right to change prices and specifications without notice. SECO-LARM is not responsible for misprints.

SECO-LARM® ENFORCER® CRIMEBUSTER® CBA SLI®

PIE-941SA-600_151005.docx