


Weather Resistant License Plate Capture Bullet Camera

CLPR66H 9-22mm F1.4 auto iris varifocal lens, dark grey housing
IR-corrected lens with external adjustments for zoom & focus

Note: Because of the special nature of this camera, during the day the scene will be monochrome. All license plates will be highlighted.


Features

- High-contrast imaging performance that delivers sharp, clear license-plate captures
- 8 pieces super high power IR LEDs work perfectly even in total darkness to deliver clear license plate images
- 9-22mm varifocal IR-corrected lens optimizes day/night performance, even in very low light conditions and captures a wide field
- Captures license plates up to 24 mph
- Weather resistant operation
- IP66 compliant
- 5 year warranty

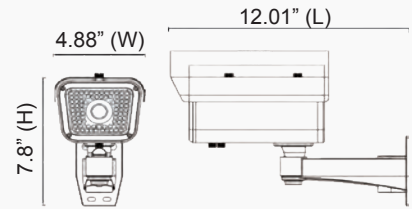

Specifications

Image Sensor	1/3" 960H CCD
Resolution.....	700 TV lines
Minimum Illumination.....	0 lux (with IR LEDs on)
Effective Pixels	1020 (H) x 508 (V)
Type.....	Monochrome
Number of IR LEDs	8 pieces super high power IR LEDs
IR Range	6.6 - 49 ft. (depending on scene reflection)
IR LED Wavelength	850nm
TV System.....	NTSC
Viewing Angle	Horizontal: 35° (wide) - 8° (tele) Vertical: 38° (wide) - 10° (tele)
S/N Ratio	More than 52db
Video Output.....	1.0Vp-p / 75 ohms
Scanning System.....	2:1 interlaced
Power Supply	12VDC (power supply not included)
Power Consumption	380mA
Operating Temperature.....	-22° F – 140° F
Housing	Compact die cast aluminum sunshield
Dimensions.....	4.88" (W) x 7.8" (H) x 12.01" (L)
Weight	4.2 lbs.

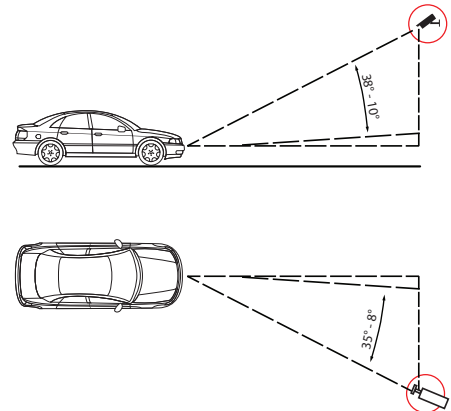

Optional Accessory



PSW5
12VDC
Power Supply

Speco Technologies is constantly developing and improving products. We reserve the right to modify product design and specifications without notice and without incurring any obligation. Spec Rev. 7/1/15

