



9K Series Grade 1 Cylindrical Locks - Levers

Federal Spec. 161

ANSI Series 4000

How To Order

9K	3	7	AB	14	C	STK	626	
Series	Backset	Core Housing	Function Code	Lever Style	Rose Style	Strike Package	Finish	Options
9K	3 – 2-3/4" 4* – 3-3/4" 5* – 5"	0 – Keyless 6 – 6-pin non-IC cylinder 7 – 7-pin housing; accepts all BEST cores	See below (Contact sales support for special functions and pricing.)	14 – Curved with return 15 – Contour angle with return 16 – Curved without return	C – 3" convex D – 3-1/2" convex K – 3" convex no ring L – 3-1/2" convex no ring	STK – Standard S3 – ANSI S3 7/8** STK 7/8*** LS – Less strike	626 690 622 626AM* Satin* 606 612 613 619 Bright* 605 611 625 618	3/4* – 3/4" throw latch AL/B* – Abrasive lever both sides AL/O* – Abrasive lever outside AL/I* – Abrasive lever inside TL/B* – Tactile lever both sides TL/O* – Tactile lever outside TL/I* – Tactile lever inside ATB – Alternate through-bolt mounting FRL* – Full radius latch LL* – Lead lined (N/A for double keyed functions) LM – Lost motion SH* – Security head screws Thin Door* – 1-3/8" OB* – non-IC zero bitted KA* – non-IC keyed alike KD* – non-IC keyed different COR* – non-IC Corbin-Russwin MED* – non-IC Medeco SAR* – non-IC Sargent SCH* – non-IC Schlage YAL* – non-IC Yale SCHRC – Schlage removable core (14 & 15 lever only) WS* – Windstorm (listed for Miami-Dade and Florida Building Code)

*Indicates extra cost. Must specify keymark and number of keys.

**S3 7/8 is the ANSI flat lip strike

***STK 7/8 is the standard flat lip strike

Function Description	Function Code	Complete with Combined Core			Less Core	W/ non-IC cyl
		Patented*	Premium	Standard		
Single Keyed						
Entrance	AB	284.68	289.26	281.24	254.89	274.94
Storeroom	D	284.68	289.26	281.24	254.89	274.94
Service station	E	284.68	289.26	281.24	254.89	274.94
Classroom	R	284.68	289.26	281.24	254.89	274.94
Dormitory	T	284.68	289.26	281.24	254.89	274.94
Special	Note**	284.68	289.26	281.24	254.89	274.94
UA	UA	284.68	289.26	281.24	254.89	274.94
Hotel (SPN-standard)	H, HJ	310.45	315.04	307.02	280.67	300.72
Double Keyed						
Corridor	C	345.39	354.56	338.52	285.82	325.92
Storeroom	G	345.39	354.56	338.52	285.82	325.92
Intruder	IN	356.85	366.01	349.98	297.28	337.37
Communicating	S	356.85	366.01	349.98	297.28	337.37
Institutional	W	356.85	366.01	349.98	297.28	337.37
Special	DR, RD	356.85	366.01	349.98	297.28	337.37
Keyless						
Passage	N, NX	N/A	N/A	N/A	182.72	NA
Exit	Y	N/A	N/A	N/A	182.72	NA
Privacy	L	N/A	N/A	N/A	211.36	NA
Patio	P	N/A	N/A	N/A	211.36	NA
Special	LL, M, Q, Z	N/A	N/A	N/A	211.36	NA
Single dummy trim	1DT	N/A	N/A	N/A	76.18	NA
Double dummy trim	2DT	N/A	N/A	N/A	151.79	NA

*Only chose one option: [OB,KA, KD] or [COR, MED, SAR, SCH, YAL]

ATTENTION: Locksets that secure both sides of the door (e.g., G, DR, IN, M, RD, S, W, XD, YD & YR) are controlled by building codes and the Life Safety Code. Delay in unlocking for rapid emergency exit could be hazardous or even fatal.

9K Series Grade 1 Cylindrical Locks (continued)

*Extra Cost Options	Option Code	Add-On
Satin finishes (per lock)	606, 612, 613, etc.	8.59
Bright finishes (per lock)	605, 625, 629, etc.	20.05
UltraShield antimicrobial finish	626AM	28.64
Thin door 1-3/8"	1-3/8"	37.80
3/4" throw latch	3/4	14.32
Windstorm	WS	14.32
Special backsets	94K / 95K	9.74
Lead lined	LL	111.69
Security head screws	SH	10.31
Abrasive lever both sides	AL/B	20.05
Abrasive lever outside	AL/O	10.02
Abrasive lever inside	AL/I	10.02
Tactile lever both sides	TL/B	40.10
Tactile lever outside	TL/O	20.05
Tactile lever inside	TL/I	20.05
7/8" Lip-to-center strike	S3 7/8 or STK 7/8	10.31
Full radius latch	FRL	9.74
Non-IC zero bitted (single keyed)	OB	20.05
Non-IC zero bitted (double keyed)	OB	40.10
Non-IC keyed alike (single keyed)	KA	20.05
Non-IC keyed alike (double keyed)	KA	40.10
Non-IC keyed different (single keyed)	KD	20.05
Non-IC keyed different (double keyed)	KD	40.10

*Only chose one option: [OB,KA, KD] or [COR, MED, SAR, SCH, YAL]

*Extra Cost Options	Option Code	Add-On
Non-IC Corbin-Russwin (single keyed)	COR	3.15
Non-IC Corbin-Russwin (double keyed)	COR	6.30
Non-IC Medeco (single keyed)	MED	3.15
Non-IC Medeco (double keyed)	MED	6.30
Non-IC Sargent (single keyed)	SAR	3.15
Non-IC Sargent (double keyed)	SAR	6.30
Non-IC Schlage (single keyed)	SCH	3.15
Non-IC Schlage (double keyed)	SCH	6.30
Non-IC Yale (single keyed)	YAL	3.15
Non-IC Yale (double keyed)	YAL	6.30


Note: These options below don't come with a cylinder. The Lock is just prepped for cylinders of these other manufacturers and comes with a throw member for that manufacturer's cylinder

Part Description	Part Number	Price
2-3/4" deadlocking latch	8KL3	34.94
3-3/4" deadlocking latch	8KL4	43.53
5" deadlocking latch	8KL5	43.53
Standard strike package	8KS2	3.44
ANSI strike package	8KS3	9.74
Throw member 6-pin / 7-pin	B54210 / B54200	0.72


Adaptation Kit

9KA	SCHRCKT	14	626
Family	Kit Type	Lever Style	Finish
9KA – Adaptation Kit	SCHRCKT – Schlage RC Adaptation Kit	14 – Curved return 15 – Contour angle return	606 626 612 613


Kit Type	Price
SCHRCKT	36.09

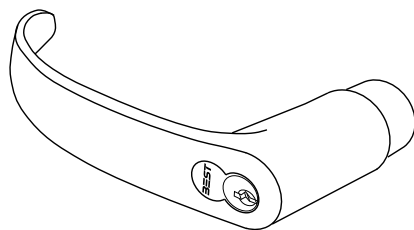


14 – Curved return

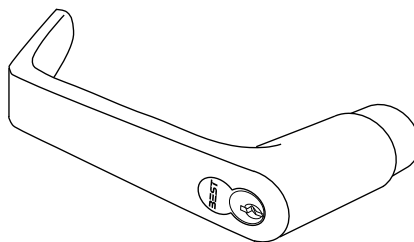


15 – Contour angle return

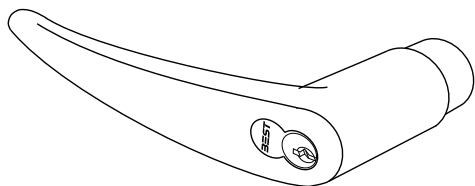

16 – Curved no return

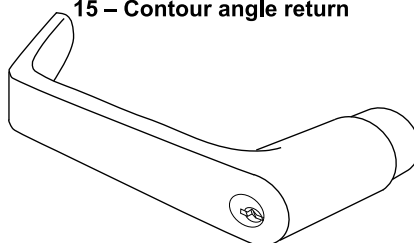

15 - Non IC contour angle return

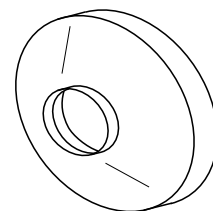

C and D Roses



K and L roses