

2"Lx.37"Wx.28"H Surface Mount Quick Connect Type



Contact Size: 2"Lx.37"Wx.28"H
(50.8mmx9.5mmx7.1mm)

Standard Magnet Size: 2"Lx.37"Wx.28"H

(50.8mmx9.5mmx7.1mm)



Standard Gap: .71"(18mm)

Colors: White, Brown, Gray, Tan



Specifications


Part Number	Gap Inch(mm)	Loop Open/Closed	Reed Form	Max. Contact Rating (W)	Max. Initial Contact Resistance (mΩ)	Max. Switching Voltage (V)	Max. Switching Current (A)
TANE-60 QC	.71"(18)	CLOSED	Normally Open	10	100	AC110/DC100	0.5
TANE-61B QC	.43"(11)	OPEN	Normally Closed	3	100	AC30/DC30	0.2
TANE-60 QC WG	1.26"(32)	CLOSED	Normally Open	10	100	AC110/DC100	0.5

OPERATING TEMPERATURE:-40°C to +60°C

Outline Dimensions

Unit: inch(mm)

TANE-60 QC/TANE-61B QC

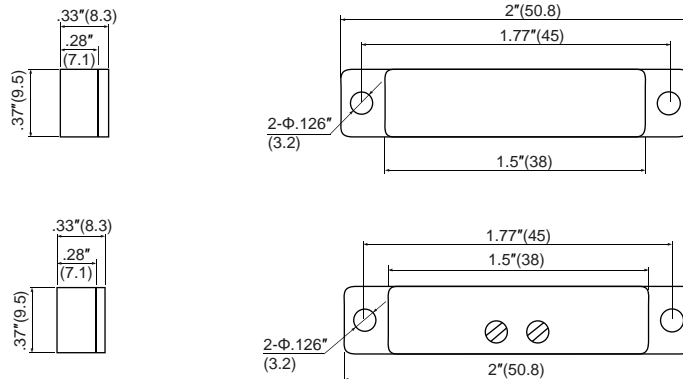

The Best Guarantee Since 1984 : \$50-1

TANE ALARM PRODUCTS

906 JERICHO TURNPIKE, NEW HYDE PARK, NY 11040

Tel: 800-852-5050 • 516-328-3351 • Fax: 516-326-9125

www.tanealarm.com • E-MAIL: info@tanealarm.com