



SPECIFICATION SHEET

09-K1218



G-TEK® KEV™ SEAMLESS KNIT KEVLAR® BLENDED GLOVE WITH NEOFOAM™ COATED GRIP ON PALM & FINGERS – 18 GAUGE, TOUCH SCREEN COMPATIBLE

- Seamless knit construction provides comfort without sacrificing dexterity
- Kevlar® fiber shell provides high tensile strength relative to its weight, is inherently cut resistant and will not melt, ignite or conduct electricity
- Neofoam™ coated palm and fingertips offers great abrasion resistance and outstanding wet/dry grip
- Knit wrist helps prevent dirt and debris from entering the glove
- 18 gauge liner for maximum dexterity
- Cotton color binding denotes sizing
- Launderable for extended life and to reduce replacement costs

APPLICATIONS

- Material handling
- General assembly
- Sanitation
- General maintenance
- Woodworking
- Waste handling
- Fishing industries
- Recycling

CARE INSTRUCTIONS

Machine wash in warm water with detergent. Rinse well and spin extract using high speed. Tumble dry on low to medium heat setting. Can be dry cleaned. Do not bleach.

TECHNICAL DATA

MATERIAL	Kevlar® / Nylon / Spandex / Steel Fiber / Neofoam™ Coating				
COLOR	Shell: ■ Gray / Coating: ■ Black				
CUFF STYLE	Elastic knit				
SIZES	S - XXL				
PACKAGING	1 pair per bag, 12 pairs per dozen, 6 dozen per case				
CASE DIMENSIONS	15" x 12.2" x 9.8" / 38cm x 31cm x 25cm				
CASE WEIGHT	S	M	L	XL	XXL
	6.6 lbs 3 kg	7.3 lbs 3.3 kg	7.7 lbs 3.5 kg	8.8 lbs 4 kg	9.5 lbs 4.3 kg
COO	China				

PERFORMANCE PROPERTIES

EN388: 4331	ASTM F2992-15 ANSI Cut Level A3 (Adopted by ANSI/ISEA 02/16)					
ABRASION	0	1	2	3	4	-
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	-
PUNCTURE	0	1	2	3	4	-




BARCODES

ITEM	BAG	DOZEN	CASE
■ 09-K1218/S	616314207877	01616314207876	02616314207875
■ 09-K1218/M	616314207860	01616314207869	02616314207868
■ 09-K1218/L	616314207853	01616314207852	02616314207851
■ 09-K1218/XL	616314207884	01616314207883	02616314207882
■ 09-K1218/XXL	616314207891	01616314207890	02616314207899

DIMENSIONS (in/cm)

	S	M	L	XL	XXL
A	8.9 / 21.8	9.4 / 22.8	9.8 / 23.5	10 / 24.8	10.4 / 25.8
B	3.3 / 8.5	3.5 / 9	3.7 / 9.5	4 / 10.2	4.2 / 10.6
H	□ Red	■ Yellow	■ Brown	■ Black	■ Blue

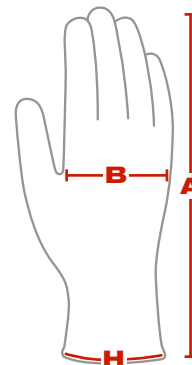

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.