



# SPECIFICATION SHEET

## 09-K3700



### KUT-GARD® TOP GRAIN GOATSKIN LEATHER GLOVE WITH KEVLAR® LINER - LIGHT WEIGHT

- Goatskin driver with Kevlar® liner, straight thumb
- Made with top grain goatskin for ultimate durability and strength
- Kevlar® brand fiber provides high tensile strength relative to its weight - up to five times stronger than steel
- Kevlar® yarn is designed to be cut resistant
- Kevlar® will not melt, ignite or conduct electricity
- Top grain goatskin provides superior comfort compared to other leather drivers
- Silicone free

### APPLICATIONS

- Glass and material handling
- Fishing industries
- Sanitation
- General maintenance
- Woodworking
- Waste handling and recycling

### CARE INSTRUCTIONS

Dry clean only

### TECHNICAL DATA

MATERIAL	Goatskin leather					
CONSTRUCTION	Shell: 100% leather / Liner: Kevlar®					
COLOR	■ Tan					
CUFF STYLE	Slip-on					
SIZES	S - XXXL					
PACKAGING	12 pairs per dozen, 6 dozen per case					
CASE	16.3" x 10.8" x 16.9" / 41.5cm x 27.5cm x 43.0cm					
CASE WEIGHT	S	M	L	XL	XXL	XXXL
	19.0 lbs 8.6 kg	20.7 lbs 9.4 kg	25.4 lbs 11.5 kg	23.6 lbs 10.7 kg	27.3 lbs 12.4 kg	27.3 lbs 12.4 kg
COO	Pakistan					



### DIMENSIONS (in/cm)

	S	M	L	XL	XXL	XXXL
<b>A</b>	9.2 / 23.3	9.3 / 23.7	9.6 / 24.5	10.0 / 25.5	10.2 / 26.0	10.4 / 26.5
<b>B</b>	4.4 / 11.3	4.6 / 11.6	4.9 / 12.5	5.1 / 12.9	5.3 / 13.5	5.7 / 14.5
<b>C</b>	2.8 / 7.2	2.8 / 7.2	3.0 / 7.6	3.2 / 8.2	3.4 / 8.6	3.5 / 9.0


### PERFORMANCE PROPERTIES

**EN388: 2241** ASTM F2992-15 ANSI Cut Level A2 (Adopted by ANSI/ISEA 02/16)  
ASTM F1790-05 ANSI Cut Level 2

	0	1	2	3	4	5
ABRASION	0	1	2	3	4	-
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	-
PUNCTURE	0	1	2	3	4	-

### BARCODES

ITEM	BAG	DOZEN	CASE
■ 09-K3700/S	---	01616314052506	02616314052505
■ 09-K3700/M	---	01616314009990	02616314009990
■ 09-K3700/L	---	01616314009983	02616314009983
■ 09-K3700/XL	---	01616314010002	02616314010002
■ 09-K3700/XXL	---	01616314010019	02616314010019
■ 09-K3700/XXXL	---	01616314052490	02616314052499

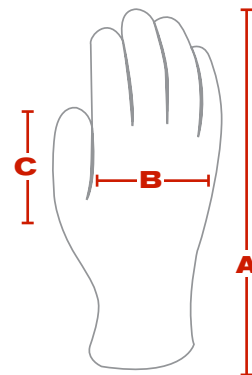

**PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®**

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | [www.pipglobal.com](http://www.pipglobal.com)

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.