



SPECIFICATION SHEET

09-K3750



3322

MAXIMUM SAFETY® ARC RATED TOP GRAIN GOATSKIN DRIVERS, STRAIGHT THUMB KEVLAR® LINED

- Top Grain Goatskin leather palm is soft, abrasion-resistant and is highly recommended for applications requiring tactile sensitivity
- Top Grain leather is smooth, provides durability and dexterity
- Kevlar® fiber liner provides high tensile strength relative to its weight, is inherently cut resistant and will not melt, ignite or conduct electricity
- 28.5 cal PPE3
- Drivers gloves feature slip-on styling to provide good fit and comfort
- Straight thumb increases comfort in closed-fisted work
- Chromium free

APPLICATIONS

- Oil and gas industries
- Protection against arc and flash fires

CARE INSTRUCTIONS

Dry clean only

TECHNICAL DATA

MATERIAL	Goatskin leather / Kevlar®					
COLOR	Natural					
CUFF STYLE	Slip-on					
SIZES	S - XXXL					
PACKAGING	12 pairs per dozen, 6 dozen per case					
CASE	16.5" x 10.4" x 16.5" / 42cm x 26.5cm x 42.0cm					
CASE WEIGHT	S	M	L	XL	XXL	XXXL
	15.8 lbs 7.1 kg	16.9 lbs 7.7 kg	17.4 lbs 7.9 kg	18.6 lbs 8.4 kg	19.5 lbs 8.8 kg	19.8 lbs 9.0 kg
COO	Pakistan					

PERFORMANCE PROPERTIES

EN388: 3322 ASTM F2992-15 ANSI Cut Level A2 (Adopted by ANSI/ISEA 02/16)
ASTM F1790-05 ANSI Cut Level 2

ABRASION	0	1	2	3	4	-
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	-
PUNCTURE	0	1	2	3	4	-


BARCODES

ITEM	BAG	DOZEN	CASE
09-K3750/S	616314061882	01616314061881	02616314061880
09-K3750/M	616314061875	01616314061874	02616314061873
09-K3750/L	616314061868	01616314061867	02616314061866
09-K3750/XL	616314061899	01616314061898	02616314061897
09-K3750/XXL	616314061905	01616314061904	02616314061903
09-K3750/XXXL	616314061912	01616314061911	02616314061910



DIMENSIONS (in/cm)

	S	M	L	XL	XXL	XXXL
A	9.3 / 23.5	9.4 / 24.0	9.6 / 24.5	10.0 / 25.5	10.2 / 26.0	10.4 / 26.5
B	4.4 / 11.3	4.6 / 11.6	4.9 / 12.5	5.1 / 12.9	5.3 / 13.5	5.7 / 14.5

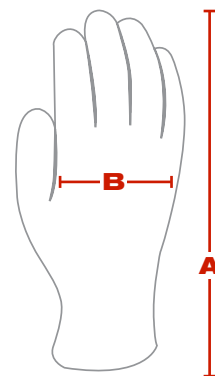

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.