



# SPECIFICATION SHEET

## 120-5150



### MAXIMUM SAFETY® TUFFMAX5

- 13 gauge orange HPPE shell with black micro-surface nitrile padded palm
- High performance polyethylene (HPPE) fiber shell is light-weight and provides excellent dexterity, tactile sensitivity and cut resistance
- MicroSurface nitrile-coated padded palm for enhanced wet & dry grip
- Thermoplastic rubber (TPR) molded finger, thumb and back of hand guards for maximum protection
- Reinforced leather between thumb and index finger
- Extended wrist
- Velcro closure for easy on/off and a secure fit

### APPLICATIONS

- Petrochem
- Construction
- Auto repair
- Demolition
- Mining
- Fabrication

### CARE INSTRUCTIONS

Hand wash only, do not bleach, hang dry.

### TECHNICAL DATA

|             |                                            |          |          |          |
|-------------|--------------------------------------------|----------|----------|----------|
| MATERIAL    | HPPE / Nitrile                             |          |          |          |
| COLOR       | Orange / Black                             |          |          |          |
| CUFF STYLE  | Continuous Knit                            |          |          |          |
| SIZES       | M - XXL                                    |          |          |          |
| PACKAGING   | 1 pair per bag, 72 pair per case           |          |          |          |
| CASE        | 22.5" x 18.9" x 10.3" / 57cm x 48cm x 27cm |          |          |          |
| CASE WEIGHT | M                                          | L        | XL       | XXL      |
|             | 36.2 lbs                                   | 37.4 lbs | 38.8 lbs | 39.6 lbs |
|             | 16.4 kg                                    | 17.0 kg  | 17.6 kg  | 18.0 kg  |
| COO         | China                                      |          |          |          |

### PERFORMANCE PROPERTIES

EN388: 4544 ASTM F2992-15 ANSI Cut Level A3 (Adopted by ANSI/ISEA 02/16)  
ASTM F1790-05 ANSI Cut Level 3

|          |   |   |   |   |   |   |
|----------|---|---|---|---|---|---|
| ABRASION | 0 | 1 | 2 | 3 | 4 | - |
| CUT      | 0 | 1 | 2 | 3 | 4 | 5 |
| TEAR     | 0 | 1 | 2 | 3 | 4 | - |
| PUNCTURE | 0 | 1 | 2 | 3 | 4 | - |


### BARCODES

| ITEM         | PAIR         | DOZEN          | CASE           |
|--------------|--------------|----------------|----------------|
| 120-5150/M   | 616314159923 | 01616314159922 | 02616314159921 |
| 120-5150/L   | 616314159916 | 01616314159915 | 02616314159914 |
| 120-5150/XL  | 616314159930 | 01616314159939 | 02616314159938 |
| 120-5150/XXL | 616314159947 | 01616314159946 | 02616314159945 |



### DIMENSIONS (in/cm)

|   | M           | L          | XL          | XXL         |
|---|-------------|------------|-------------|-------------|
| A | 10.4 / 26.5 | 10.6 / 27  | 11.1 / 28.2 | 11.3 / 28.8 |
| B | 4.3 / 11    | 4.4 / 11.3 | 4.5 / 11.5  | 4.6 / 11.8  |

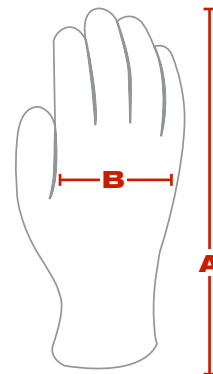

**PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®**

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | [www.pipglobal.com](http://www.pipglobal.com)

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.