



PROTECTIVE INDUSTRIAL PRODUCTS

125-468 Specification Sheet

HI-VISIBILITY LEATHER DRIVERS

PRODUCT DESCRIPTION:

Hi-visibility leather driver gloves, insulated with 3M Thinsulate, hi-vis fabric back and cuffs, top grain pigskin leather, keystone thumb.

- Hi-vis orange nylon back with 3M® reflective band over knuckle provides workers with great visibility in high risk applications.
- Top grain pigskin provides great protection in wet and cold applications.
- Consistent grading and superior workmanship.

Applications:

Ideal for outdoor, cold general work applications, refrigerated warehousing and highway construction.



TECHNICAL DATA:

Material: Pigskin leather/nylon

Color: Natural, hi-vis orange, hi-vis yellow

Cuff Style: Slip on

Available Sizes: S - XL

Packaging: 12 pair per dozen, 6 dozen per case

Case Dimensions (S) cm - 48.5 x 25.5 x 38.5 / in - 19.1 x 10.0 x 15.2

(M) cm - 48.5 x 25.5 x 38.5 / in - 19.1 x 10.0 x 15.2

(L) cm - 48.5 x 26.5 x 39.5 / in - 19.1 x 10.4 x 15.6

(XL) cm - 48.5 x 26.5 x 39.5 / in - 19.1 x 10.4 x 15.6

Case Weight: (S) 17.6 lbs / 8.0 kg **(L)** 23.1 lbs / 10.5 kg


(M) 22.0 lbs / 10.0 kg **(XL)** 24.25 lbs / 11.0 kg

Country of Origin/Harmonization Code: China/4203.29.3020

DIMENSIONS:

Size Available	S	M	L	XL
Over Length (cm) - A	23.5	24.2	25.2	26.0
(in)	9.3	9.5	9.9	10.2
Palm Width (cm) - B	11.5	12.0	12.7	13.5
(in)	4.5	4.7	5.0	5.3
Tolerance	0.5 cm / 0.25 in			
Thickness	0.9 (+/- 0.1) mm			

BARCODE #	DOZEN	CASE
125-468/XL	01616314020636	02616314020636
125-468/L	01616314020605	02616314020605
125-468/M	01616314020612	02616314020612
125-468/S	01616314020629	02616314020629

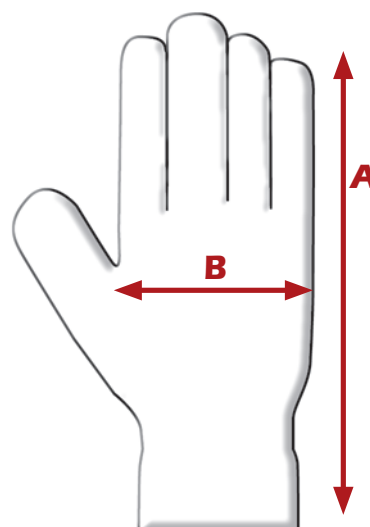

This document is the property of PIP and the information contained herein is proprietary to PIP.