



PROTECTIVE INDUSTRIAL PRODUCTS

130-100WM Specification Sheet

100% COTTON DRESS GLOVE

PRODUCT DESCRIPTION:

Cabaret 100% cotton dress glove, white, open cuff.

- Constructed in full fashion pattern with fourchettes and set-in thumbs for a tailored fit.
- Shirred elastic wrist.
- Three lines of raised stitching on back.

Applications:

Used for formal occasions by police, firemen, waiters, marching bands, military and pallbearers.

TECHNICAL DATA:

Material: 100% cotton

Construction: Seamless knit cotton

Color: White

Cuff Style: Open

Available Sizes: S - XL

Packaging: 12 pair per dozen, 25 dozen per case

Case Dimensions: (S) cm - 48 x 24 x 36 / in - 18.9 x 9.4 x 14.2

(M) cm - 49 x 25 x 36 / in - 19.3 x 9.8 x 14.2

(L) cm - 50 x 25 x 36 / in - 19.7 x 9.8 x 14.2

(XL) cm - 51 x 26 x 36 / in - 20.1 x 10.2 x 14.2

Case Weight: (S) 17.6 lbs / 8.0 kg **(M)** 19.8 lbs / 9.0 kg

(M) 19.8 lbs / 9.0 kg **(L)** 22.0 lbs / 10.0 kg

Country of Origin/Harmonization Code: China/6116.92.7460


Laundering Instructions:

Recommend washing gloves in tempered water not exceeding 104° F or 40° C. A mild commercial laundry soap or detergent should be used. Wash in a 5-10 minute cycle time. Rinse in cold water. Tumble dry at temperature not exceeding 104° F or 40° C.



DIMENSIONS:

<u>Size Available</u>	<u>S</u>	<u>M</u>	<u>L</u>	<u>XL</u>
Over Length (cm) – A	23.3	24.0	24.7	25.4
(in)	9.2	9.4	9.7	10.0
Palm Width (cm) – B	8.5	9	9.5	10
(in)	3.3	3.5	3.7	3.9

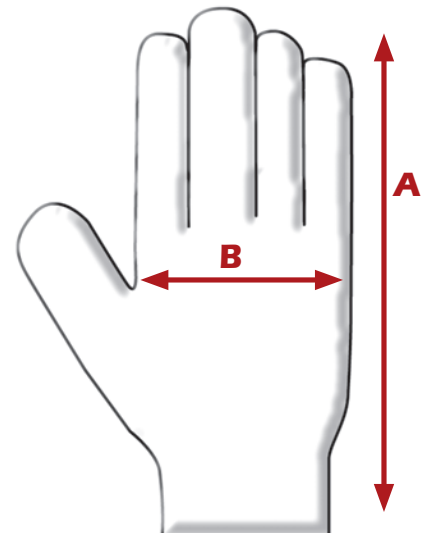

<u>BARCODE #</u>	<u>DOZEN</u>	<u>CASE</u>
130-100WM/XL	01616314053732	02616314053731
130-100WM/L	01616314053701	02616314053700
130-100WM/M	01616314053718	02616314053717
130-100WM/S	01616314053725	02616314053724

This document is the property of PIP and the information contained herein is proprietary to PIP.