



SPECIFICATION SHEET

15-340



4544

G-TEK® SUPRENE™ BLENDED GLOVE WITH POLYURETHANE COATED SMOOTH GRIP

- Suprene™ fiber shell is 100 times stronger than steel and is amongst the highest performing fibers in cut and tear resistance
- Seamless knit construction provides comfort without sacrificing dexterity
- Polyurethane coated palm and fingertips for great abrasion resistance, excellent puncture resistance and outstanding wet/dry grip
- Knit wrist helps prevent dirt and debris from entering the glove
- Cotton color binding denotes sizing
- Launderable for extended life and to reduce replacement costs

APPLICATIONS

- Electronics
- General duty
- Parts assembly
- Construction

CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C).


TECHNICAL DATA

MATERIAL	Suprene™ Engineered Yarn / Polyurethane Coating					
CONSTRUCTION	Seamless Knit					
COLOR	Shell: ■ Tan / Coating: ■ Gray					
SIZES	XS - XXL					
PACKAGING	1 pair per bag, 12 pairs per dozen, 6 dozen per case					
CASE DIMENSIONS	15" x 11.8" x 10.6" / 38cm x 30cm x 27cm					
CASE WEIGHT	XS	S	M	L	XL	XXL
	7.5 lbs 3.4 kgs	8 lbs 3.7 kgs	8.8 lbs 4 kgs	10.4 lbs 4.7 kgs	11 lbs 4.9 kgs	11.3 lbs 5.2 kgs
COO	China					



DIMENSIONS (in/cm)

	XS	S	M	L	XL	XXL
A	8.6 / 22	9 / 23	9.4 / 24	9.8 / 25	10.2 / 26	10.6 / 27
B	3.4 / 8.8	3.5 / 9	3.7 / 9.5	4 / 10.3	4.1 / 10.6	4.3 / 10.8
H	■ Purple	■ Red	■ Yellow	■ Brown	■ Black	■ Sky Blue

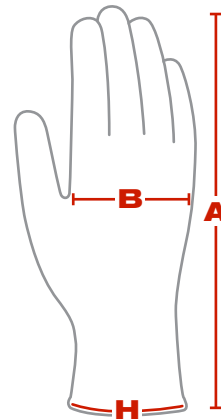

PERFORMANCE PROPERTIES

EN388: 4544 ASTM F2992-15 ANSI Cut Level A4 (Adopted by ANSI/ISEA 02/10)

ABRASION	0	1	2	3	4	-
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	-
PUNCTURE	0	1	2	3	4	-

BARCODES

ITEM	BAG	DOZEN	CASE
■ 15-340/XS	616314219351	01616314219350	02616314219359
■ 15-340/S	616314219337	01616314219336	02616314219335
■ 15-340/M	616314219320	01616314219329	02616314219328
■ 15-340/L	616314219313	01616314219312	02616314219311
■ 15-340/XL	616314219344	01616314219343	02616314219342
■ 15-340/XXL	616314219368	01616314219367	02616314219366

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.