



SPECIFICATION SHEET

16-330



4342

G-TEK® POLYKOR™ BLENDED GLOVE WITH DOUBLE-DIPPED NITRILE COATED MICRO-SURFACE GRIP

- Seamless construction offers increased comfort and breathability
- PolyKor™ shell is lightweight and provides excellent dexterity, tactile sensitivity and cut resistance
- Double-dipped nitrile micro-surface coated palm and fingertips help extend the life of the glove and provide excellent abrasion resistance
- Knit wrist helps prevent dirt and debris from entering the glove
- Cotton color binding denotes sizing
- Washable, resistant to chemicals, water, and ultraviolet light
- Extended cuff
- Compliant with FDA Part 177 - Indirect food activities: Polymers. Subpart C - Substances for use only as components of articles intended for repeated use. Sec. 177.2600

APPLICATIONS

- Electronics
- Glass cutting
- Sheet metal handling
- General duty
- Parts assembly
- Sharp small parts handling

CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C).

TECHNICAL DATA

| | | | | | | |
|-----------------|---|---------|-------|--------|--------|---------|
| MATERIAL | PolyKor™ Fiber / Nitrile | | | | | |
| CONSTRUCTION | Seamless Knit | | | | | |
| COLOR | Shell: ■ Blue/White / Coating: ■ Black | | | | | |
| CUFF STYLE | Continuous knit | | | | | |
| SIZES | XS - XXL | | | | | |
| PACKAGING | 1 pair per bag, 12 pairs per dozen, 6 dozen per case | | | | | |
| COMPLIANT WITH | FDA PART 177 - Indirect food activities: Polymers. Subpart C - Substances for use only as components of articles intended for repeated use. Sec. 177.2600 | | | | | |
| CASE DIMENSIONS | 22.4" x 13.4" x 7.5" / 57cm x 34cm x 19cm | | | | | |
| CASE WEIGHT | XS | S | M | L | XL | XXL |
| | 10 lb | 10.5 lb | 11 lb | 12 lb | 13 lb | 13.5 lb |
| | 4.5 kg | 4.8 kg | 5 kg | 5.4 kg | 5.9 kg | 6.1 kg |
| COO | China | | | | | |

PERFORMANCE PROPERTIES

| | | | | | | |
|-------------|--|---|---|---|---|---|
| EN388: 4342 | ASTM F2992-15 ANSI Cut Level A2 (Adopted by ANSI/ISEA 02/16) | | | | | |
| | ASTM F1790-05 ANSI Cut Level 2 | | | | | |
| ABRASION | 0 | 1 | 2 | 3 | 4 | - |
| CUT | 0 | 1 | 2 | 3 | 4 | - |
| TEAR | 0 | 1 | 2 | 3 | 4 | - |
| PUNCTURE | 0 | 1 | 2 | 3 | 4 | - |




BARCODES

| ITEM | BAG | DOZEN | CASE |
|--------------|-----|----------------|----------------|
| ■ 16-330/XS | --- | 01616314130662 | 02616314130661 |
| ■ 16-330/S | --- | 01616314130648 | 02616314130647 |
| ■ 16-330/M | --- | 01616314130631 | 02616314130630 |
| ■ 16-330/L | --- | 01616314130624 | 02616314130623 |
| ■ 16-330/XL | --- | 01616314130655 | 02616314130654 |
| ■ 16-330/XXL | --- | 01616314130697 | 02616314130678 |

DIMENSIONS (in/cm)

| | XS | S | M | L | XL | XXL |
|---|------------|-------------|-----------|-------------|-------------|--------------|
| A | 9.2 / 23.5 | 9.65 / 24.5 | 10 / 25.5 | 10.4 / 26.5 | 10.8 / 27.5 | 11.22 / 28.5 |
| B | 3.2 / 8.1 | 3.4 / 8.6 | 3.6 / 9.2 | 3.9 / 10 | 4.2 / 10.6 | 4.3 / 10.8 |
| H | ■ Purple | ■ Red | ■ Yellow | ■ Brown | ■ Black | ■ Sky Blue |

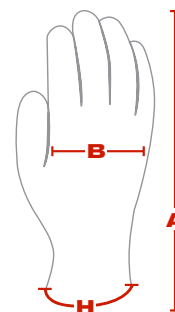

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.